


WBT Performance Cable Tray PreForm Tee

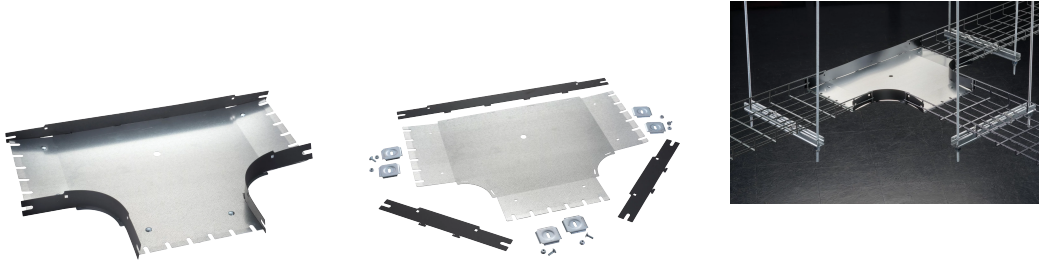

nVent CADDY WBT Performance Cable Tray PreForm is a cleaner, faster, more uniform engineered solution for pathway bends, tees and intersections. The PreForm Tee is a revolutionary, time-saving solution for seamless intersections ensuring clean engineering precision and effortless attachment without cutting or configuring. Due to its unique design, this offering provides up to 60% reduction in labor and time compared to traditional methods while maintaining flexibility and cost-effectiveness in tray pathway retrofits.

FEATURES

Routes cable systems in two directions

Maintains UL classification throughout installation

SPECIFICATIONS

Finish: Pregalvanized

Material: Steel

Table 1/1

Catalog Number	Color	Height	Width	Length	Unit Weight
WBTT2X4		50.8 mm	94.46 mm	526.26mm	0.454 kg
WBTT2X4BA	Black	50.8 mm	94.46 mm	526.26mm	0.454 kg
WBTT2X4WH	White	50.8 mm	94.46 mm	526.26mm	0.454 kg
WBTT2X6		50.8 mm	144.48 mm	576.28mm	1.361 kg

Catalog Number	Color	Height	Width	Length	Unit Weight
WBTT2X6BA	Black	50.8 mm	144.48 mm	576.28mm	1.361 kg
WBTT2X6WH	White	50.8 mm	144.48 mm	576.28mm	1.361 kg
WBTT2X8		50.8 mm	194.46 mm	626.67mm	1.814 kg
WBTT2X8BA	Black	50.8 mm	194.46 mm	626.67mm	1.814 kg
WBTT2X8WH	White	50.8 mm	194.46 mm	626.67mm	1.814 kg
WBTT2X12		50.8 mm	294.49 mm	726.29mm	2.722 kg
WBTT2X12BA	Black	50.8 mm	294.49 mm	726.29mm	2.722 kg
WBTT2X12WH	White	50.8 mm	294.49 mm	726.29mm	2.722 kg
WBTT2X16		50.8 mm	394.49 mm	826.29mm	3.629 kg
WBTT2X16BA	Black	50.8 mm	394.49 mm	826.29mm	3.629 kg
WBTT2X16WH	White	50.8 mm	394.49 mm	826.29mm	3.629 kg
WBTT2X18		50.8 mm	444.5 mm	876.3mm	4.536 kg
WBTT2X18BA	Black	50.8 mm	444.5 mm	876.3mm	4.536 kg
WBTT2X18WH	White	50.8 mm	444.5 mm	876.3mm	4.536 kg
WBTT2X20BA	Black	50.8 mm	494.51 mm	926.31mm	5.897 kg
WBTT2X20WH	White	50.8 mm	494.51 mm	926.31mm	5.897 kg
WBTT2X24		50.8 mm	594.51 mm	1026.31mm	7.257 kg
WBTT2X24BA	Black	50.8 mm	594.51 mm	1026.31mm	7.257 kg

Catalog Number	Color	Height	Width	Length	Unit Weight
WBTT2X24WH	White	50.8 mm	594.51 mm	1026.31mm	7.257 kg

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical
Support

Europe

Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europe

Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC

Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE

