

# nVent CADDY Cat HP J-Hook with Multi-Function Clip

## Data Solutions



### CERTIFICATIONS



### FEATURES

Quick attachment to threaded rod or wire

Fully adjustable and easy to relocate to accommodate changes once installed

Provides optimal support for high-performance data cable, up to and including Cat 5e, Cat 6, Cat 6A, Cat 7 and fibre optic

Provides superior fill capacity and load rating over most other non-continuous cable support alternatives

Rounded edges on J-Hooks provide proper bend radius support for high performance data cables

Cost effective alternative to expensive cable tray

Complies with EN 50174-2

Meets ISO®/IEC 14763-2, ANSI®/TIA 568 and ANSI®/TIA 569

Increased capability and application options by combining 4Z and 6Z products into one enhanced and efficient offering

Improved multi-function clip allows for optimized inventory while reducing job site scheduling risks associated with multiple SKUs

## SPECIFICATIONS

**Material:** Steel; Spring Steel

Table 1/2						
Catalog Number	Finish	Color	Diameter (Ø)	Area	Cable Capacity, Cat 5e	Cable Capacity, Cat 6
CAT16HP4Z34	Pregalvanized, nVent CADDY Armour		25mm	690mm <sup>2</sup>	20	15
CAT21HP4Z34	Pregalvanized, nVent CADDY Armour		33.3mm	1174mm <sup>2</sup>	50	40
CAT21HPWH4Z34	Pregalvanized, Painted, nVent CADDY Armour	White	33.3mm	1174mm <sup>2</sup>	50	40
CAT32HP4Z34	Pregalvanized, nVent CADDY Armour		50mm	2561mm <sup>2</sup>	90	60
CAT32HPBA4Z34	Pregalvanized, Painted, nVent CADDY Armour	Black	50mm	2561mm <sup>2</sup>	90	60
CAT32HPWH4Z34	Pregalvanized, Painted, nVent CADDY Armour	White	50mm	2561mm <sup>2</sup>	90	60
CAT48HP4Z34	Pregalvanized, nVent CADDY Armour		75mm	5974mm <sup>2</sup>	200	150
CAT64HP4Z34	Pregalvanized, nVent CADDY Armour		100mm	9987mm <sup>2</sup>	330	220
CAT16HP8Z34	Pregalvanized, nVent CADDY Armour		25mm	690mm <sup>2</sup>	20	15
CAT21HP8Z34	Pregalvanized, nVent CADDY Armour		33.3mm	1174mm <sup>2</sup>	50	40
CAT32HP8Z34	Pregalvanized, nVent CADDY Armour		50mm	2561mm <sup>2</sup>	90	60
CAT48HP8Z34	Pregalvanized, nVent CADDY Armour		75mm	5974mm <sup>2</sup>	200	150

CatalogNumber	Finish	Color	Diameter (Ø)	Area	Cable Capacity, Cat 5e	Cable Capacity, Cat 6
CAT64HP8Z34	Pregalvanized, nVent CADDY Armour		100mm	9987mm <sup>2</sup>	330	220

Table 2/2

Catalog Number	Cable Capacity, Cat 6A	Wire Size	Rod Size (RS)	Static Load
CAT16HP4Z34	10	3.9 – 4.8mm	4, 6, 8, 10	130N
CAT21HP4Z34	25	3.9 – 4.8mm	4, 6, 8, 10	130N
CAT21HPWH4Z34	25	3.9 – 4.8mm	4, 6, 8, 10	130N
CAT32HP4Z34	35	3.9 – 4.8mm	4, 6, 8, 10	130N
CAT32HPBA4Z34	35	3.9 – 4.8mm	4, 6, 8, 10	130N
CAT32HPWH4Z34	35	3.9 – 4.8mm	4, 6, 8, 10	130N
CAT48HP4Z34	80	3.9 – 4.8mm	4, 6, 8, 10	130N
CAT64HP4Z34	140	3.9 – 4.8mm	4, 6, 8, 10	130N
CAT16HP8Z34	10	1mm min	14, 18	220N
CAT21HP8Z34	25	1mm min	14, 18	220N
CAT32HP8Z34	35	1mm min	14, 18	220N
CAT48HP8Z34	80	1mm min	14, 18	220N
CAT64HP8Z34	140	1mm min	14, 18	220N


## ADDITIONAL PRODUCT DETAILS

Non-continuous supports may not exceed spacing of 5' (1.5 m) per TIA 569-C.9.7 and EN 50174-2.

Cable capacity is calculated based on a 70% fill rate.

## DIAGRAMS

---

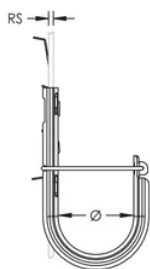

## WARNING

---

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.



Our powerful portfolio of brands:

**CADDY   ERICO   HOFFMAN   ILSCO   SCHROFF   TRACHTE**