

1 Hole Lug, GL Style



FEATURES

Provides an efficient bolting surface for grounding and power applications

Electrolytic grade copper

For use with nVent ERICO Cadweld type GL connections only

SPECIFICATIONS

Material: Copper

Type: NEMA®

Finish: Tinned

Table 1/2

Catalog Number	Height (H)	Length (L)	Width (W)	Thickness (T)	A	Hole Size (HS)
B121CE	11.18 mm	36.58mm	25.4 mm	3.18 mm	15.9 mm	14.29 mm
B121QQ	11 mm	38.5mm	25.4 mm	3.2 mm	16 mm	14.3 mm
B121DE	11.18 mm	37.34mm	25.4 mm	4.76 mm	15.9 mm	14.29 mm
B121SQ	11 mm	36.5mm	25.4 mm	4.76 mm	16 mm	14 mm
B121EE	11.18 mm	38.1mm	25.4 mm	6.35 mm	15.9 mm	14.29 mm

CatalogNumber	Height (H)	Length (L)	Width (W)	Thickness (T)	A	Hole Size (HS)
B121EG	11.18 mm	38.1mm	38.1 mm	6.35 mm	15.9 mm	14.29 mm



Table 2/2

Catalog Number	Angle (a)	Equivalent Conductor Size
B121CE	90 °	80.63mm ²
B121QQ	90 °	81mm ²
B121DE	105 °	120.94mm ²
B121SQ	90 °	121mm ²
B121EE	135 °	161.26mm ²
B121EG	135 °	241.89mm ²

ADDITIONAL PRODUCT DETAILS

For sizes not listed, contact us.

DIAGRAMS

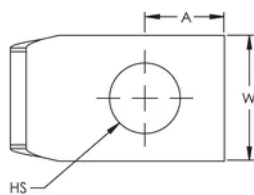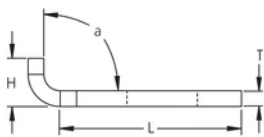

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Our powerful portfolio of brands:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE