

Air Terminal Base, Bracket Mount



CERTIFICATIONS



FEATURES

Mounts to satellite dishes or other non-standard structures

Adjustable swivel allows air terminals to be vertically positioned


SPECIFICATIONS

Conductor Size, UL: Class 1 - Class 2 (4/0 Max)

Table 1/1

Catalog Number	Material	Thread Size (TS)	Depth (D)	Height (H)	Width (W)	Unit Weight
LPA34958	Aluminum	5/8" UNC	76.2mm	91.44 mm	66.04 mm	0.73 kg
LPA34912	Aluminum	1/2" UNC	76.2mm	91.44 mm	66.04 mm	0.73 kg
LPC34938	Copper	3/8" UNC	76.2mm	91.44 mm	66.04 mm	0.82 kg
LPC34912	Copper	1/2" UNC	76.2mm	91.44 mm	66.04 mm	0.82 kg

DIAGRAMS

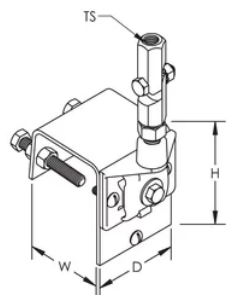

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

⚠ WARNING: This product can expose you to chemicals including lead, which is known to the State of California to cause cancer and birth defects or other reproductive harm. For more information go to www.P65Warnings.ca.gov.

North America

+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical
Support

Europe

Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europe

Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC

Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE