

Compression 45° Angle Lug



FEATURES

Tin plated for corrosion prevention

Annealed copper eases the crimping operation

Optimized sizes to the most efficient electrical conductivity

Best mechanical behavior (vibration/pull-out); DIN EN 61373 Class 1B "Railway Applications"

Markings on barrel for crimping

Consistent material thickness, precise diameter and accurate cable fit; DIN46235

Flat contact surface by special angle punching process

SPECIFICATIONS

Angle (a): 45 °

Material: Copper

Finish: Tinned


Table 1/1

Catalog Number	Lug/Connector Type	Conductor Size	Hole Size (HS)	Length (L)	Width (W)	Tool/Die Type
PKS1201245H	Heavy-Duty DIN46235	120 mm ² Stranded, 250 kcmil Stranded	13 mm	71mm	32 mm	M2M or M2H/PKM2, M3H or M3B/PKM3, MLB/PKML

CatalogNumber	Lug/Connector Type	Conductor Size	Hole Size (HS)	Length (L)	Width (W)	Tool/Die Type
PKS1501245H	Heavy-Duty DIN46235	150 mm ² Stranded, 300 kcmil Stranded	13 mm	71mm	34 mm	M2M or M2H/PKM2, M3H or M3B/PKM3, MLB/PKML
PKS1851245H	Heavy-Duty DIN46235	185 mm ² Stranded, 350 kcmil Stranded	13 mm	81mm	37 mm	M2M or M2H/PKM2, M3H or M3B/PKM3, MLB/PKML
PKS2401245H	Heavy-Duty DIN46235	240 mm ² Stranded, 500 kcmil Stranded	13 mm	81mm	42 mm	M2M or M2H/PKM2, M3H or M3B/PKM3
RKS0061945	Standard	#6 Stranded, 16 mm ² Stranded	12.95 mm	58mm	21 mm	M2M or M2H/RKM2, M3H or M3B/RKM3, MLB/RKML
RKS1201245	Standard	120 mm ² Stranded, 250 kcmil Stranded	13 mm	51mm	28 mm	M2M or M2H/RKM2, M3H or M3B/RKM3, MLB/RKML
RKS1501245T	Standard	150 mm ² Stranded, 300 kcmil Stranded	13 mm	61mm	31 mm	M2M or M2H/RKM2, M3H or M3B/RKM3, MLB/RKML
RKS1851245T	Standard	185 mm ² Stranded, 350 kcmil Stranded	13 mm	61mm	35 mm	M2M or M2H/RKM2, M3H or M3B/RKM3, MLB/RKML
RKS2401245T	Standard	240 mm ² Stranded, 500 kcmil Stranded	13 mm	71mm	39 mm	M2M or M2H/RKM2, M3H or M3B/RKM3, MLB/RKML
RKS3001245T	Standard	300 mm ² Stranded, 600 kcmil Stranded	13 mm	86mm	43 mm	M2M or M2H/RKM2, M3H or M3B/RKM3
RKS4001245T	Standard	400 mm ² Stranded, 800 kcmil Stranded	13 mm	86mm	49 mm	M3H or M3B/RKM3

CatalogNumber	Lug/Connector Type	Conductor Size	Hole Size (HS)	Length (L)	Width (W)	Tool/Die Type
PKS1201645H	Heavy-Duty DIN46235	120 mm ² Stranded, 250 kcmil Stranded	15 mm	71mm	32 mm	M2M or M2H/PKM2, M3H or M3B/PKM3, MLB/PKML
PKS1501645H	Heavy-Duty DIN46235	150 mm ² Stranded, 300 kcmil Stranded	15 mm	71mm	34 mm	M2M or M2H/PKM2, M3H or M3B/PKM3, MLB/PKML
PKS1851645H	Heavy-Duty DIN46235	185 mm ² Stranded, 350 kcmil Stranded	15 mm	81mm	37 mm	M2M or M2H/PKM2, M3H or M3B/PKM3, MLB/PKML
PKS2401645H	Heavy-Duty DIN46235	240 mm ² Stranded, 500 kcmil Stranded	15 mm	81mm	42 mm	M2M or M2H/PKM2, M3H or M3B/PKM3
RKS1201645T	Standard	120 mm ² Stranded, 250 kcmil Stranded	15 mm	51mm	28 mm	M2M or M2H/RKM2, M3H or M3B/RKM3, MLB/RKML
RKS1501645T	Standard	150 mm ² Stranded, 300 kcmil Stranded	15 mm	61mm	31 mm	M2M or M2H/RKM2, M3H or M3B/RKM3, MLB/RKML
RKS1851645T	Standard	185 mm ² Stranded, 350 kcmil Stranded	15 mm	61mm	35 mm	M2M or M2H/RKM2, M3H or M3B/RKM3, MLB/RKML
RKS2401645T	Standard	240 mm ² Stranded, 500 kcmil Stranded	15 mm	71mm	39 mm	M2M or M2H/RKM2, M3H or M3B/RKM3, MLB/RKML
RKS3001645T	Standard	300 mm ² Stranded, 600 kcmil Stranded	15 mm	86mm	43 mm	M2M or M2H/RKM2, M3H or M3B/RKM3
RKS4001645T	Standard	400 mm ² Stranded, 800 kcmil Stranded	15 mm	86mm	49 mm	M3H or M3B/RKM3

DIAGRAMS

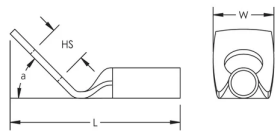

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical
Support

Europe

Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europe

Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC

Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE