

Drill Distance Gauge, Four Plates



FEATURES

Used for making precise drill hole spacings of ± 1 mm (0.039")

Common applications include fishplates and insulated rail joints

SPECIFICATIONS

Drill Guide Included: No
Material: Steel

Table 1/2


Catalog Number	Rail Type	Length (L)	Width (W)	Height (H)	A	B
DDGNP4AM40	NP4AM	400mm	87.9 mm	50 mm	40 mm	40 mm
DDGNP4AM45	NP4AM	415mm	87.9 mm	50 mm	45 mm	45 mm
DDG750900750	STR40	520mm	87.9 mm	50 mm	75 mm	90 mm
DDG570660570	S49	375mm	119.9 mm	60 mm	57 mm	66 mm

Table 2/2

Catalog Number	C
DDGNP4AM40	40 mm

Catalog Number	C
DDGNP4AM45	45 mm
DDG750900750	75 mm
DDG570660570	57 mm

DIAGRAMS

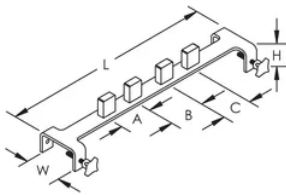

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Our powerful portfolio of brands:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE