

DT Panel Protector Replacement Module



The nVent ERICO DT Panel Protector Replacement Module is designed to seamlessly integrate into the EDT and DT product family, providing a reliable replacement solution. This module allows end users to easily open the cabinet and replace the modules on the din rail within the cabinets, ensuring minimal downtime and maintenance effort.

CERTIFICATIONS



FEATURES

Scales with voltage requirements

Easy installation on din rails within cabinets

Supports self-service replacement

Patented Lever-Assisted Technology

SPECIFICATIONS


Table 1/2

Catalog Number	Height (H)	Width (W)	Depth (D)	Nominal System Voltage (Un)	Max Continuous Operating Voltage (Uc)	Nominal Discharge Current (In), IEC
DT2150DTXM	64.21 mm	45.01 mm	2.56mm	120 V	150 V	20kA 8/20 μ s
DT2275DTXM	64.21 mm	45.01 mm	2.56mm	240 V	275 V	20kA 8/20 μ s
DT2180DTXM	64.21 mm	45.01 mm	2.56mm	120 V	150 V	20kA 8/20 μ s

CatalogNumber	Height (H)	Width (W)	Depth (D)	NominalSystem Voltage(Un)	MaxContinuous Operating Voltage (Uc)	Nominal Discharge Current (In),IEC
DT2510DTXM	64.21 mm	45.01 mm	2.56mm	480 V	510 V	20kA 8/20 μ s

Table 2/2				
Catalog Number	Nominal Discharge Current (In), UL	Frequency	Temperature	Enclosure Material
DT2150DTXM	20kA 8/20 μ s	50 Hz Min	-35 to 85 °C	UL 94V-0 Thermoplastic
DT2275DTXM	20kA 8/20 μ s	50 Hz Min	-35 to 85 °C	UL 94V-0 Thermoplastic
DT2180DTXM	20kA 8/20 μ s	50 Hz Min	-35 to 85 °C	UL 94V-0 Thermoplastic
DT2510DTXM	20kA 8/20 μ s	50 Hz Min	-35 to 85 °C	UL 94V-0 Thermoplastic

DIAGRAMS

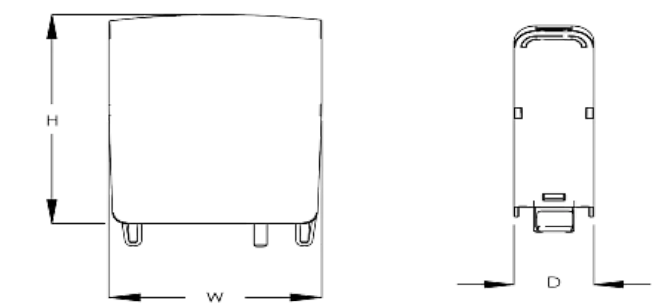

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Our powerful portfolio of brands:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE