

Female-Male Swivel Adaptor, Imperial Thread



CERTIFICATIONS



FEATURES

Allows air terminal to be positioned vertically when base is on a sloping roof

Male thread includes locknut for positioning

SPECIFICATIONS

Table 1/2

Catalog Number	Material	Finish	Thread Size 1 (TS1)	Thread Size 2 (TS2)	Length 1 (L1)	Length 2 (L2)
LPA2832F2M	Aluminum		1/2" UNC	1/2" UNC	44.45 mm	69.85 mm
LPA2842F5M	Aluminum		1/2" UNC	5/8" UNC	44.45 mm	69.85 mm
LPA2845F2M	Aluminum		5/8" UNC	1/2" UNC	44.45 mm	69.85 mm
LPA2855F5M	Aluminum		5/8" UNC	5/8" UNC	44.45 mm	69.85 mm


CatalogNumber	Material	Finish	Thread Size 1 (TS1)	Thread Size 2 (TS2)	Length 1 (L1)	Length 2 (L2)
LPS2832F2M	Stainless Steel 304 (EN 1.4301)		1/2" UNC	1/2" UNC	44.45 mm	69.85 mm
LPS2845F2M	Stainless Steel 304 (EN 1.4301)		5/8" UNC	1/2" UNC	44.45 mm	69.85 mm
LPS2855F5M	Stainless Steel 304 (EN 1.4301)		5/8" UNC	5/8" UNC	44.45 mm	69.85 mm
LPC2813F3M	Copper		3/8" UNC	3/8" UNC	44.45 mm	69.85 mm
LPC281L3F3M	Copper	Tinned	3/8" UNC	3/8" UNC	44.45 mm	69.85 mm
LPC2822F3M	Copper		1/2" UNC	3/8" UNC	44.45 mm	69.85 mm
LPC2823F2M	Copper		3/8" UNC	1/2" UNC	44.45 mm	69.85 mm
LPC2832F2M	Copper		1/2" UNC	1/2" UNC	44.45 mm	69.85 mm
LPC2842F5M	Copper		1/2" UNC	5/8" UNC	44.45 mm	69.85 mm
LPC2845F2M	Copper		5/8" UNC	1/2" UNC	44.45 mm	69.85 mm
LPC2855F5M	Copper		5/8" UNC	5/8" UNC	44.45 mm	69.85 mm

Table 2/2

Catalog Number	Unit Weight	Certifications
LPA2832F2M	0.07 kg	E202878-Combined_CoC, E202878-Combined_CoC
LPA2842F5M	0.07 kg	E202878-Combined_CoC, E202878-Combined_CoC
LPA2845F2M	0.07 kg	E202878-Combined_CoC, E202878-Combined_CoC
LPA2855F5M	0.07 kg	
LPS2832F2M	0.22 kg	

Catalog Number	Unit Weight	Certifications
LPS2845F2M	0.22 kg	
LPS2855F5M	0.22 kg	
LPC2813F3M	0.23 kg	E202878-Combined_CoC, E202878-Combined_CoC
LPC281L3F3M	0.23 kg	
LPC2822F3M	0.23 kg	E202878-Combined_CoC, E202878-Combined_CoC
LPC2823F2M	0.23 kg	E202878-Combined_CoC, E202878-Combined_CoC
LPC2832F2M	0.23 kg	E202878-Combined_CoC, E202878-Combined_CoC
LPC2842F5M	0.23 kg	E202878-Combined_CoC, E202878-Combined_CoC
LPC2845F2M	0.23 kg	E202878-Combined_CoC, E202878-Combined_CoC
LPC2855F5M	0.23 kg	E202878-Combined_CoC, E202878-Combined_CoC

DIAGRAMS

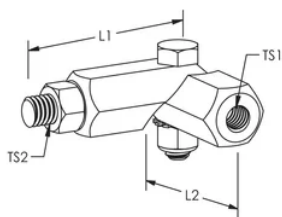

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

⚠ WARNING: This product can expose you to chemicals including lead, which is known to the State of California to cause cancer and birth defects or other reproductive harm. For more information go to www.P65Warnings.ca.gov.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Our powerful portfolio of brands:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE