

Rail Profile Template



FEATURES

Provides specific, safe and easy positioning of hole height on the rail profile

Universal rail profile templates can accommodate multiple rail profiles

Suitable for use with nVent ERICO SBMV2, SBMV4, SBME48VDC and SBME230VAC rail drill machines

Installs easily on rail drill machines

SPECIFICATIONS

Hole Size (HS): 6.5 mm

Diameter (Ø): 54 mm

Material: Steel

Table 1/1


Catalog Number	Template Type	Width (W)	Rail Type	Hole Height (HH)
RPT100LB	Regular	82.5 mm	100 lb ARAB	66.8mm
RPT115LB	Regular	82.5 mm	115 lb AREA	75.7mm
RPT132RE	Regular	82.5 mm	132 lb RE	81.3mm
RPT136RE	Regular	82.5 mm	136 lb RE, TR68	85.3mm
RPT141AB	Regular	82.5 mm	141 lb AB	88.1mm

Catalog Number	Template Type	Width (W)	Rail Type	Hole Height (HH)
RPT43KG625	Regular	82.5 mm	43 kg	62.5mm
RPT50KG63	Regular	82.5 mm	50 kg	63mm
RPT60KG738	Regular	82.5 mm	60 kg	73.8mm
RPT70LBASCS	Regular	82.5 mm	70 lb ASCS	52.1mm
RPT90LB655	Regular	82.5 mm	90 lb ARA, TR45	66.5mm
RPT90LBARAA	Regular	82.5 mm	90 lb ARAA	64.5mm
RPTAS41KG603	Regular	82.5 mm	AS41	60.3mm
RPTAS4758	Regular	82.5 mm	AS47	58mm
RPTAS47619	Regular	82.5 mm	AS47	61.9mm
RPTAS50KG67	Regular	82.5 mm	AS50	67mm
RPTAS5364	Regular	82.5 mm	AS53	64mm
RPTAS53AS60NAX	Regular	82.5 mm	AS46, AS53	62.5mm
RPTAS6068	Regular	82.5 mm	AS60	68mm
RPTAS60KG745	Regular	82.5 mm	AS60	74.5mm
RPTBH95RBS64	Regular	82.5 mm	BH95RBS	64.69mm
RPTBHP42KG58	Regular	82.5 mm	BHP42	58mm
RPTBS100A	Regular	82.5 mm	BS100A	76.2mm
RPTBS80A	Regular	82.5 mm	BS80A	65.53mm

Catalog Number	Template Type	Width (W)	Rail Type	Hole Height (HH)
RPTBS90A56	Regular	82.5 mm	BS90A	56mm
RPTB50T675	Regular	82.5 mm	50 kg	67.5mm
RPTIR52KG69	Regular	82.5 mm	52 kg	69mm
RPTK4063	Regular	82.5 mm	K40	63mm
RPTNP4AM805	Regular	82.5 mm	NP4AM	80.5mm
RPTNP4AM865	Regular	82.5 mm	NP4AM	86.5mm
RPTNP4AM893	Regular	82.5 mm	NP4AM	93mm
RPTR65785	Regular	82.5 mm	R65	78.5mm
RPTRI6087	Regular	82.5 mm	RI60	87mm
RPTRP42	Regular	82.5 mm	RP42	60.5mm
RPTRP54	Regular	82.5 mm	RP54	70mm
RPTS41595	Regular	82.5 mm	S41	59.5mm
RPTS49475	Regular	82.5 mm	S49	47.5mm
RPTUIC5472	Regular	82.5 mm	UIC	72mm
RPTUIC6074	Regular	82.5 mm	UIC60	74mm
RPTUIC60763	Regular	82.5 mm	UIC60	76.3mm
RPTUNI	Universal	95 mm	S49, S54, UIC60	62.5mm
RPTUNIVABC	Universal	95 mm	BS90A, UIC54, UIC60	70mm

Catalog Number	Template Type	Width (W)	Rail Type	Hole Height (HH)
RPTUNIVEFG	Universal	95 mm	AS50, AS60, BHP42	74.5mm
RPTVRC50CN	Regular	82.5 mm	VRC50	68.5mm
RPTVRC60CN	Regular	82.5 mm	VRC60	79mm

DIAGRAMS

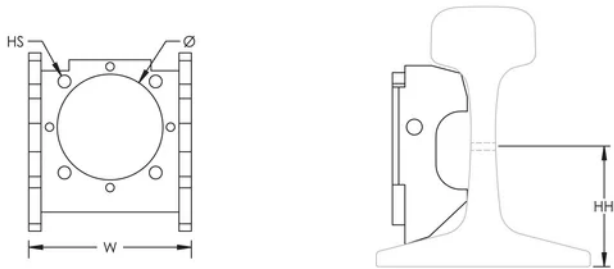

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221
 Option 1 – Customer Care
 Option 2 – Technical Support

Europe

Netherlands:
 +31 800-0200135
 France:
 +33 800 901 793

Europe

Germany:
 800 1890272
 Other Countries:
 +31 13 5835404

APAC

Shanghai:
 + 86 21 2412 1618/19
 Sydney:
 +61 2 9751 8500



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE