

DRG Asymmetric Profile



CERTIFICATIONS



FEATURES

Rapid assembly of all kinds of frameworks

High mechanical resistance

High corrosion resistance

Conforms to EN 60715 and 50035 and DIN 46277

RoHS compliant

SPECIFICATIONS


Table 1/2

Catalog Number	Article Number	Material	Finish	Height (H)	Width (W)	Length (L)
DRG2M	558000	Steel	Electrogalvanized	32 mm	15 mm	2000mm

Table 2/2

Catalog Number	Article Number	Thickness (T)	A	Unit Weight
DRG2M	558000	1.5 mm	9 mm	1.4 kg

DIAGRAMS

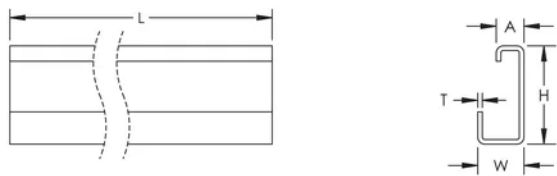

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical
Support

Europe

Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europe

Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC

Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE