


Cable Entry Divider, CCFD, 45x45x18mm, Black

CATALOG NUMBER

CCFD4

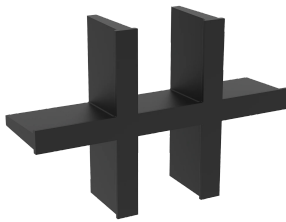

With the click-in CCFD inlays, dimensioning of the frame opening can be adjusted based on the grommet being used.

INDUSTRY STANDARDS

UL 508A Component Recognized; Type 1, 12, 4X (indoor only); File No. E61997

UL94 V-0 Flammability

NEMA Type 1, 12, 4X (indoor only)

CE

IP66

FEATURES

Description: With the CCFD click-in inlays, dimensioning of the frame opening can be adjusted based on to the grommet being used. An audible click confirms correct installation. This flexible cable entry configuration enables you to accommodate various requirements for cables, lines, tubing, pneumatic and hydraulic lines.

Finish: Black

Flammability: UL94 V-0

Material: Polyamide 6.6 / TPE

Pack quantity: 5pcs

Protection: IP66, NEMA 1, 4x, 12 (Indoor use only)

Temperature resistance: -40°C to +90°C

PRODUCT ATTRIBUTES

Article Number: 58333

Height: 45mm

Width: 45mm

Depth: 17.7mm

Material: Plastic

Finish: Untreated

Color: Black

Operating Temperature: -40 to 120°C

Weight: 0.0054421768707483kg

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE