

nVent LENTON Interlok No-Thread Bar Positioner



The nVent LENTON Interlok No-Thread Bar Positioner provides a hard stop to prevent the over-insertion of rebar during pre-cast installations. Designed for use with the nVent LENTON Interlok No-Thread Grout-Fill Coupler, this robust system ensures secure and accurate placement with every use. Both easy-to-install and remove, the Interlok No-Thread Bar Positioner is reusable with minimal wear and tear, ultimately saving valuable time and money on the job site.

FEATURES

Durable and reusable

Ensures connection capacity

Used in combination with the nVent LENTON Interlok Toggle Form Mount

Digital model available in nVent BIM Library


SPECIFICATIONS

Table 1/1

Catalog Number	Rebar Size, Canada	Rebar Size, US	Rebar Size, Metric	Bar Depth (BD)	Length (L)	Unit Weight
LKNT20BP	20M	#6	20 mm	176mm	133mm	0.72 kg
LKNT22BP		#7	22 mm	193mm	156mm	0.76 kg
LKNT25BP	25M	#8	25 mm	212mm	178mm	0.81 kg
LKNT28BP	30M	#9	28 mm	230mm	203mm	0.86 kg
LKNT32BP		#10	32 mm	252mm	229mm	0.92 kg

CatalogNumber	Rebar Size, Canada	Rebar Size, US	Rebar Size, Metric	Bar Depth (BD)	Length (L)	Unit Weight
LKNT36BP	35M	#11	36 mm	276mm	251mm	1 kg

DIAGRAMS

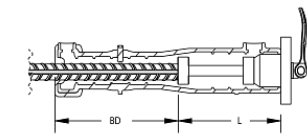

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical
Support

Europe

Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europe

Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC

Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE