

P9 Position Coupler, Plain



CERTIFICATIONS



FEATURES

Designed to splice the same diameter bars

Designed to splice two curved, bent or straight bars, when neither bar can be rotated and where the ongoing bar is free to move in its axial direction

SPECIFICATIONS

Finish: Plain

Material: Steel

100% U.S. Domestic Content: Yes

Table 1/2

Catalog Number	Rebar Size, Metric	Rebar Size, US	Rebar Size, Canada	Diameter (Ø)	Length 1 (L1)	Length 2 (L2)
EL20P9	20 mm	#6	20M	46 mm	109 mm	124 mm
EL22P9	22 mm	#7		46 mm	116 mm	132 mm

CatalogNumber	Rebar Size, Metric	Rebar Size, US	Rebar Size, Canada	Diameter (Ø)	Length 1 (L1)	Length 2 (L2)
EL25P9	25 mm	#8	25M	46 mm	125 mm	140 mm
EL28P9	28 mm	#9	30M	64 mm	129 mm	144 mm
EL32P9	32 mm	#10		64 mm	135 mm	151 mm
EL36P9	36 mm	#11	35M	64 mm	145 mm	160 mm
EL38P9	38 mm	#12		76 mm	149 mm	164 mm
EL43TP9	43 mm	#14	45M	76 mm	224 mm	245 mm
EL57TP9	57 mm	#18	55M	102 mm	267 mm	288 mm

Table 2/2						
Catalog Number	Bar Depth (BD)	Bar Gap 1 (BG1)	Bar Gap 2 (BG2)	Coupler Body (CB)	Unit Weight	Certifications
EL20P9	28mm	53mm	68mm	70mm	1.22 kg	LA City Approval, IAPMO®-UES
EL22P9	32mm	52mm	68mm	78mm	1.26 kg	LA City Approval, IAPMO®-UES
EL25P9	34mm	57mm	72mm	86mm	1.29 kg	LA City Approval, IAPMO®-UES
EL28P9	38mm	53mm	68mm	90mm	2.75 kg	LA City Approval, IAPMO®-UES
EL32P9	40mm	55mm	71mm	97mm	2.75 kg	LA City Approval, IAPMO®-UES
EL36P9	43mm	59mm	74mm	106mm	2.86 kg	IAPMO®-UES, LA City Approval
EL38P9	44mm	61mm	76mm	94mm	4.04 kg	
EL43TP9	56mm	112mm	133mm	127mm	5.62 kg	IAPMO®-UES, LA City Approval

CatalogNumber	Bar Depth (BD)	Bar Gap 1(BG1)	Bar Gap 2(BG2)	Coupler Body (CB)	Unit Weight	Certifications
EL57TP9	71mm	125mm	146mm	156mm	11.29 kg	LA City Approval, IAPMO®-UES


Designed to Meet:

AASHTO;ABNT NBR 8548:1984;ACI 318 Type 1 (125% Specified Yield);ACI 318 Type 2 (Specified Tensile);ACI 349;ACI 359;AS3600

ADDITIONAL PRODUCT DETAILS

Bar dimensions and weights listed may vary by region. Coupler sizes not shown may be available by special order. Contact your nVent LENTON representative for more information.

DIAGRAMS

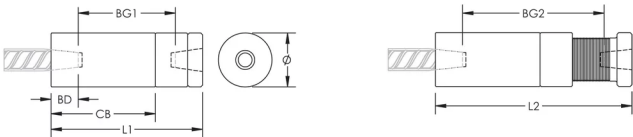

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent’s instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221
 Option 1 – Customer Care
 Option 2 – Technical Support

Europe

Netherlands:
 +31 800-0200135
 France:
 +33 800 901 793

Europe

Germany:
 800 1890272
 Other Countries:
 +31 13 5835404

APAC

Shanghai:
 + 86 21 2412 1618/19
 Sydney:
 +61 2 9751 8500



Our powerful portfolio of brands:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE