


CompacPRO Complete Desktop Case, Unshielded

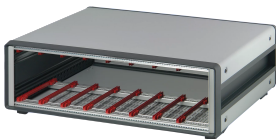

The pre-configured nVent SCHROFF CompacPRO case provides electronics protection for 19" assemblies such as plug-in units and euroboards. The aluminum die cast frame and sidepanels guarantee a robust solution. In addition an extensive accessory range is available.

CERTIFICATIONS



FEATURES

Desktop case pre-configured in accordance with IEC 60297-3-101 for 19" components

Aluminum construction ensures robust solution

Side panel with integrated handle function

For backplane mounting with insulation strips

Ventilation slots in rear panel

Ventilation slots in base plate

IP 20 in accordance with IEC 60529

Front and rear identical, depth-symmetrical construction

GND / earthing connections in accordance with (please see catalog page 5.76)

Conforms with DIN EN 62368-1

SPECIFICATIONS

Product Type:	Case
Type:	Case for 19" Components

Table 1/3

Catalog Number	Rack Height	Height	Rack Width	Width	Depth	Package Quantity
14575-114	3U	147.1mm	28HP	186mm	271mm	1
14575-115	3U	147.1mm	28HP	186mm	331mm	1
14575-134	3U	147.1mm	42HP	257mm	271mm	1
14575-135	3U	147.1mm	42HP	257mm	331mm	1
14575-136	3U	147.1mm	42HP	257mm	391mm	1
14575-154	3U	147.1mm	63HP	364mm	271mm	1
14575-155	3U	147.1mm	63HP	364mm	331mm	1
14575-156	3U	147.1mm	63HP	364mm	391mm	1
14575-174	3U	147.1mm	84HP	471mm	271mm	1
14575-175	3U	147.1mm	84HP	471mm	331mm	1
14575-176	3U	147.1mm	84HP	471mm	391mm	1
14575-178	3U	147.1mm	84HP	471mm	511mm	1
14575-476	6U	280.5mm	84HP	471mm	391mm	1
14575-477	6U	280.5mm	84HP	471mm	511mm	1

Table 2/3

Catalog Number	Usable Height	Usable Width	Front Frame Construction	Cooling Option	Complies With	EMC Shielding
14575-114	129.3mm	148mm	Single Piece	No	IEC 60297-3-103	No

CatalogNumber	Usable Height	Usable Width	Front Frame Construction	Cooling Option	Complies With	EMC Shielding
14575-115	129.3mm	148mm	Single Piece	No	IEC 60297-3-103	No
14575-134	129.3mm	219mm	Single Piece	No	IEC 60297-3-103	No
14575-135	129.3mm	219mm	Single Piece	No	IEC 60297-3-103	No
14575-136	129.3mm	219mm	Single Piece	No	IEC 60297-3-103	No
14575-154	129.3mm	326mm	Single Piece	No	IEC 60297-3-103	No
14575-155	129.3mm	326mm	Single Piece	No	IEC 60297-3-103	No
14575-156	129.3mm	326mm	Single Piece	No	IEC 60297-3-103	No
14575-174	129.3mm	432mm	Single Piece	No	IEC 60297-3-103	No
14575-175	129.3mm	432mm	Single Piece	No	IEC 60297-3-103	No
14575-176	129.3mm	432mm	Single Piece	No	IEC 60297-3-103	No
14575-178	129.3mm	432mm	Single Piece	No	IEC 60297-3-103	No
14575-476	262.9mm	432mm	Single Piece	No	IEC 60297-3-103	No
14575-477	262.9mm	432mm	Single Piece	No	IEC 60297-3-103	No

Table 3/3

Catalog Number	Finish	Material	Protection Rating	Static Load	Quick Ship
14575-114	Anodized, Powder Coated	Aluminum	IP20	30kg	No
14575-115	Anodized, Powder Coated	Aluminum	IP20	30kg	No
14575-134	Anodized, Powder Coated	Aluminum	IP20	30kg	No
14575-135	Anodized, Powder Coated	Aluminum	IP20	30kg	No

Catalog Number	Finish	Material	Protection Rating	Static Load	Quick Ship
14575-136	Anodized, Powder Coated	Aluminum	IP20	30kg	No
14575-154	Anodized, Powder Coated	Aluminum	IP20	30kg	No
14575-155	Anodized, Powder Coated	Aluminum	IP20	30kg	No
14575-156	Anodized, Powder Coated	Aluminum	IP20	30kg	No
14575-174	Anodized, Powder Coated	Aluminum	IP20	30kg	No
14575-175	Anodized, Powder Coated	Aluminum	IP20	30kg	No
14575-176	Anodized, Powder Coated	Aluminum	IP20	30kg	No
14575-178	Anodized, Powder Coated	Aluminum	IP20	30kg	No
14575-476	Anodized, Powder Coated	Aluminum	IP20	30kg	No
14575-477	Anodized, Powder Coated	Aluminum	IP20	30kg	No

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE