


## Static Handle Plastic in Trapezoid Form, Grey

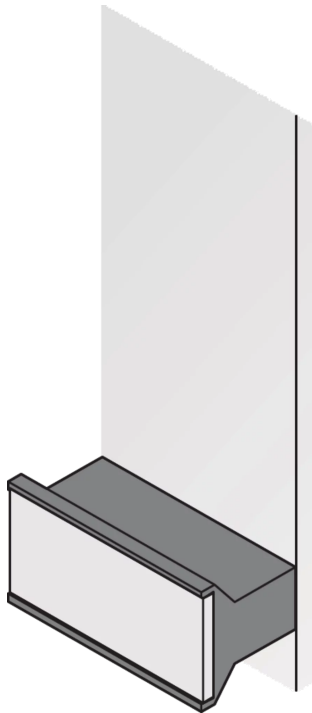

The static plastic handle, trapezoid form in grey color can be mounted to a front panel for extraction of the PCB.

### CERTIFICATIONS

---



### FEATURES

---

With separate identification plate, Al 1.5 mm

Handle, PC, UL 94 V-0

### SPECIFICATIONS

---

<b>Works With:</b>	Front Panels
<b>Product Type:</b>	Handle
<b>Material:</b>	Polyphenylene Ether
<b>Type:</b>	Static

Table 1/2

Catalog Number	Rack Width	Package Quantity	Handle Type	Flammability Rating	Color	Color Code
20808-003	5HP	1	Trapezoid, Static	UL® 94V-0	Light Grey	RAL 7035
20808-004	10HP	1	Trapezoid, Static	UL® 94V-0	Light Grey	RAL 7035
20808-009	40HP	1	Trapezoid, Static	UL® 94V-0	Grey	
20808-012	61HP	1	Trapezoid, Static	UL® 94V-0	Grey	
20808-060	6HP	1	Trapezoid, Static	UL® 94V-0	Light Grey	RAL 7035
20808-061	7HP	1	Trapezoid, Static	UL® 94V-0	Light Grey	RAL 7035
20808-062	8HP	1	Trapezoid, Static	UL® 94V-0	Light Grey	RAL 7035
20808-063	9HP	1	Trapezoid, Static	UL® 94V-0	Grey	
20808-064	12HP	1	Trapezoid, Static	UL® 94V-0	Light Grey	RAL 7035
20808-065	14HP	1	Trapezoid, Static	UL® 94V-0	Light Grey	RAL 7035
20808-066	21HP	1	Trapezoid, Static	UL® 94V-0	Light Grey	RAL 7035
20808-067	28HP	1	Trapezoid, Static	UL® 94V-0	Light Grey	RAL 7035
20808-068	42HP	1	Trapezoid, Static	UL® 94V-0	Light Grey	RAL 7035
20809-294	3HP	1	Trapezoid, Static	UL® 94V-0	Light Grey	RAL 7035
20809-295	4HP	1	Trapezoid, Static	UL® 94V-0	Light Grey	RAL 7035

Table 2/2

Catalog Number	Complies With	Depth (D)	Height (H)	Width (W)	Quick Ship
20808-003	EN 45545-2, R22-R24, HL3, IEC 60297-3-101	14mm	15.4mm	24mm	No


Catalog Number	Complies With	Depth (D)	Height (H)	Width (W)	Quick Ship
20808-004	EN 45545-2, R22-R24, HL3, IEC 60297-3-101	14mm	15.4mm	49.4mm	No
20808-009	EN 45545-2, R22-R24, HL3, IEC 60297-3-101			201.8mm	No
20808-012	EN 45545-2, R22-R24, HL3, IEC 60297-3-101			308.5mm	No
20808-060	EN 45545-2, R22-R24, HL3, IEC 60297-3-101	14mm	15.4mm	29mm	No
20808-061	EN 45545-2, R22-R24, HL3, IEC 60297-3-101	14mm	15.4mm	34.1mm	No
20808-062	EN 45545-2, R22-R24, HL3, IEC 60297-3-101	14mm	15.4mm	39.2mm	No
20808-063	EN 45545-2, R22-R24, HL3, IEC 60297-3-101			44.3mm	No
20808-064	EN 45545-2, R22-R24, HL3, IEC 60297-3-101	14mm	15.4mm	59.6mm	No
20808-065	EN 45545-2, R22-R24, HL3, IEC 60297-3-101	14mm	15.4mm	69.7mm	No
20808-066	EN 45545-2, R22-R24, HL3, IEC 60297-3-101	14mm	15.4mm	105.2mm	No
20808-067	EN 45545-2, R22-R24, HL3, IEC 60297-3-101	14mm	15.4mm	140.8mm	No
20808-068	EN 45545-2, R22-R24, HL3, IEC 60297-3-101	14mm	15.4mm	212mm	No
20809-294	EN 45545-2, R22-R24, HL3, IEC 60297-3-101	16.3mm	15.4mm	13.8mm	No
20809-295	EN 45545-2, R22-R24, HL3, IEC 60297-3-101	16.3mm	15.4mm	18.9mm	No

## ADDITIONAL PRODUCT DETAILS

Please take into consideration that deliveries may be carried out in the stated SPQs (SPQ, e.g. 5 pieces, 10 pieces, 50 pieces, etc.). Differing order quantities (e.g. 2 pieces) may be changed to the next possible delivery quantity = Standard Pack Quantity.

Cannot be used together with fixing clip (21101-239).

## DIAGRAMS

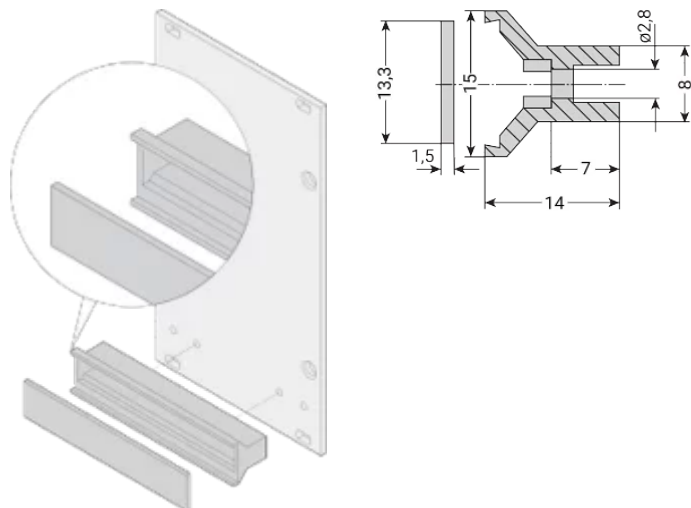

## WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

### North America

All locations  
+1.763.422.2661  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

### Europe

Straubenhardt, Germany  
+49.7082.794.0  
Betschdorf, France  
+33.3.88.90.64.90  
Warsaw, Poland  
+48.22.209.98.35  
Assago, Italy  
+39.02.932.7141  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

### Asia

Shanghai, China  
+86.21.2412.6943  
Qingdao, China  
+86.532.8771.6101  
Singapore  
+65.6768.5800  
Shin-Yokohama, Japan  
+81.45.476.0271  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

### Middle East & India

Dubai, United Arab Emirates  
+971.4.378.1700  
Bangalore, India  
+91.80.6715.2001  
Istanbul, Turkey  
+90.216.250.7374  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)



Our powerful portfolio of brands:

**CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE**