


# 2000 Beam Clamp Kit

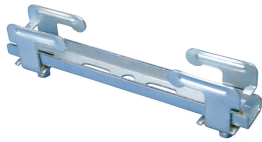

## FEATURES

Light duty system

Includes clamp and U channel

## SPECIFICATIONS

**Finish:** Electrogalvanized

**Material:** Steel

Table 1/2

| Catalog Number | Article Number | Length (L) | A     | B     | C     | D     |
|----------------|----------------|------------|-------|-------|-------|-------|
| 2300EG         | 570160         | 300mm      | 25 mm | 25 mm | 65 mm | 25 mm |
| 2200EG         | 570140         | 200mm      | 25 mm | 25 mm | 65 mm | 25 mm |
| 2400EG         | 570180         | 400mm      | 25 mm | 25 mm | 65 mm | 25 mm |

Table 2/2

| Catalog Number | Article Number | E       | Static Load 1 (F1) | Static Load 2 (F2) | Static Load 3 (F3) |
|----------------|----------------|---------|--------------------|--------------------|--------------------|
| 2300EG         | 570160         | 30.5 mm | 1700N              | 490N               | 340N               |
| 2200EG         | 570140         | 30.5 mm | 1700N              | 490N               | 340N               |


| Catalog Number | Article Number | E       | Static Load 1 (F1) | Static Load 2 (F2) | Static Load 3 (F3) |
|----------------|----------------|---------|--------------------|--------------------|--------------------|
| 2400EG         | 570180         | 30.5 mm | 1700N              | 490N               | 340N               |

- Thickness (T): 2 mm
- Screw Diameter (Sc): 6
- Hole Size (HS): 11 mm
- Height (H): 12 mm
- Width (W): 25 mm
- Torque (TQ): 30 N·m
- Flange Thickness (FT): 11 mm Max

### ADDITIONAL PRODUCT DETAILS

For a secure grip the channel must extend to the outer edge of each beam clamp.

### DIAGRAMS

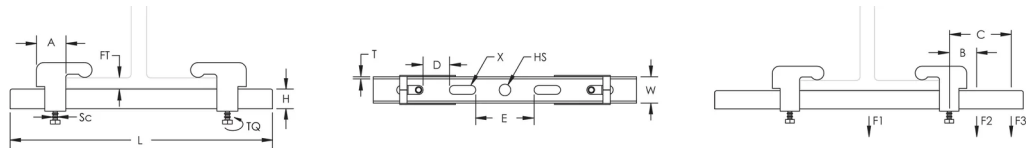

### WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

#### North America

+1.800.753.9221  
 Option 1 – Customer Care  
 Option 2 – Technical Support

#### Europe

Netherlands:  
 +31 800-0200135  
 France:  
 +33 800 901 793

#### Europe

Germany:  
 800 1890272  
 Other Countries:  
 +31 13 5835404

#### APAC

Shanghai:  
 + 86 21 2412 1618/19  
 Sydney:  
 +61 2 9751 8500



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE

