


# Eurorack Slide Rail, 25 kg

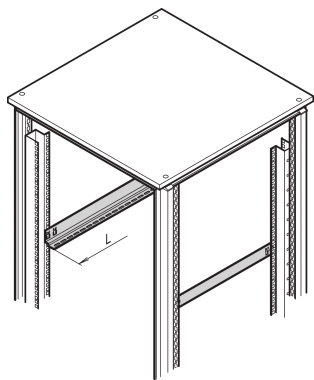

Eurorack Slide Rail with 25 kg load capacity for mounting on the cabinet uprights or 19" panel/slide mounts. The slide rail supports shelf of heavy 19" Chassis.

## CERTIFICATIONS



## FEATURES

St, 1.5 mm, finish AlZn

Static load-carrying capacity 25 kg per pair

Support shelf of heavy 19" chassis

For assembly on the 19" panel/slide mounts

Wide support surface

Can be attached in 1 U increments

## SPECIFICATIONS

**Static Load:** 25kg

**Product Type:** Slide Rail

**Material:** Steel

Table 1/1

| Catalog Number | Depth | Length | Package Quantity | Finish | Quick Ship |
|----------------|-------|--------|------------------|--------|------------|
|----------------|-------|--------|------------------|--------|------------|

|           |       |       |    |                      |    |
|-----------|-------|-------|----|----------------------|----|
| 22127-094 | 600mm | 420mm | 2  | Aluminum-Zinc Plated | No |
| 25127-575 | 800mm | 512mm | 2  | Aluminum-Zinc Plated | No |
| 22127-095 | 800mm | 620mm | 2  | Aluminum-Zinc Plated | No |
| 22127-096 | 900mm | 717mm | 2  | Aluminum-Zinc Plated | No |
| 21127-197 | 600mm | 420mm | 10 | Aluminum-Zinc Plated | No |
| 21127-198 | 800mm | 620mm | 10 | Aluminum-Zinc Plated | No |
| 21127-199 | 900mm | 720mm | 10 | Aluminum-Zinc Plated | No |

## ADDITIONAL PRODUCT DETAILS

Standard distance for servers d = 740 mm. For assembly 4 pieces panel/slide mounts are necessary (please order separately, see panel/slide mount).

## WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

### North America

All locations  
+1.763.422.2661  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

### Europe

Straubenhardt, Germany  
+49.7082.794.0  
Betschdorf, France  
+33.3.88.90.64.90  
Warsaw, Poland  
+48.22.209.98.35  
Assago, Italy  
+39.02.932.7141  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

### Asia

Shanghai, China  
+86.21.2412.6943  
Qingdao, China  
+86.532.8771.6101  
Singapore  
+65.6768.5800  
Shin-Yokohama, Japan  
+81.45.476.0271  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

### Middle East & India

Dubai, United Arab Emirates  
+971.4.378.1700  
Bangalore, India  
+91.80.6715.2001  
Istanbul, Turkey  
+90.216.250.7374  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)



Our powerful portfolio of brands:

**CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE**