


# Guide Rail Multi Piece, Mid-Piece Aluminium/Plastic Extrusion

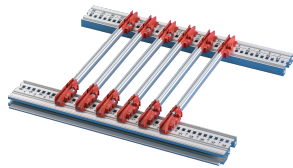

Guide rail mid-piece for individual multi-piece guide rails out of plastic or Aluminum extrusion. Suitable for Standard, Accessory, 4.4" PCB types and end pieces with coding.

## CERTIFICATIONS



## FEATURES

Middle profile for mounting guide rails for 2 mm groove width

2 plastic end pieces are required; these are pushed on to both ends of the middle profile

Guide rails can be clipped into horizontal rails (Al extrusion) or into 1.5 mm thick plates

Storage temperature: from -40 °C ... 130 °C

## SPECIFICATIONS

|                        |                                                                                    |
|------------------------|------------------------------------------------------------------------------------|
| <b>Product Family:</b> | EuropacPRO; RatiopacPRO; RatiopacPRO AIR; CompacPRO; PropacPRO; MultipacPRO; Inpac |
| <b>Product Type:</b>   | Guide Rail                                                                         |
| <b>Type:</b>           | Middle Section                                                                     |

Table 1/2

| Catalog Number | Material | Color  | Package Quantity | Board Depth | Groove Width | Color Code |
|----------------|----------|--------|------------------|-------------|--------------|------------|
| 34560-891      | Aluminum | Silver | 1                | 160mm       | 2            |            |

| CatalogNumber | Material | Color  | Package Quantity | Board Depth | Groove Width | Color Code |
|---------------|----------|--------|------------------|-------------|--------------|------------|
| 34560-892     | Aluminum | Silver | 1                | 220mm       | 2            |            |
| 34560-893     | Aluminum | Silver | 1                | 280mm       | 2            |            |
| 34560-900     | Aluminum | Silver | 1                | 1000mm      | 2            |            |
| 34564-891     | PVC      | Grey   | 1                | 160mm       | 2            | RAL 7035   |
| 34564-892     | PVC      | Grey   | 1                | 220mm       | 2            | RAL 7035   |
| 34564-893     | PVC      | Grey   | 1                | 280mm       | 2            | RAL 7035   |
| 34564-900     | PVC      | Grey   | 1                | 1000mm      | 2            | RAL 7035   |

Table 2/2

| Catalog Number | Finish   | Works With               | Quick Ship |
|----------------|----------|--------------------------|------------|
| 34560-891      | Anodized | Subracks, Cases, Chassis | No         |
| 34560-892      | Anodized | Subracks, Cases, Chassis | No         |
| 34560-893      | Anodized | Subracks, Cases, Chassis | No         |
| 34560-900      | Anodized | Subracks, Cases, Chassis | No         |
| 34564-891      |          | Subracks, Cases, Chassis | No         |
| 34564-892      |          | Subracks, Cases, Chassis | No         |
| 34564-893      |          | Subracks, Cases, Chassis | No         |
| 34564-900      |          | Subracks, Cases, Chassis | No         |

## ADDITIONAL PRODUCT DETAILS

Delivery may be in Standard Pack Quantity (SPQ). Pricing is per individual item.

One guide rail consists of 1 pair of head pieces and 1 profile piece.

Please take into consideration that deliveries may be carried out in the stated SPQs (SPQ, e.g. 5 pieces, 10 pieces, 50 pieces, etc.). Differing order quantities (e.g. 2 pieces) may be changed to the next possible delivery quantity = Standard Pack Quantity.

**WARNING**

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

**North America**

All locations  
+1.763.422.2661  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

**Europe**

Straubenhardt, Germany  
+49.7082.794.0  
Betschdorf, France  
+33.3.88.90.64.90  
Warsaw, Poland  
+48.22.209.98.35  
Assago, Italy  
+39.02.932.7141  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

**Asia**

Shanghai, China  
+86.21.2412.6943  
Qingdao, China  
+86.532.8771.6101  
Singapore  
+65.6768.5800  
Shin-Yokohama, Japan  
+81.45.476.0271  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

**Middle East & India**

Dubai, United Arab Emirates  
+971.4.378.1700  
Bangalore, India  
+91.80.6715.2001  
Istanbul, Turkey  
+90.216.250.7374  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)



Our powerful portfolio of brands:

**CADDY   ERICO   HOFFMAN   ILSCO   SCHROFF   TRACHTE**