


# Interscale Fan Holder With Fans

Interscale Fan Holder With Fans, for desktop cases and 19" chassis. Available in different sizes and with three fan versions, with a air flow volume from 10 to 170 m<sup>3</sup>/h.

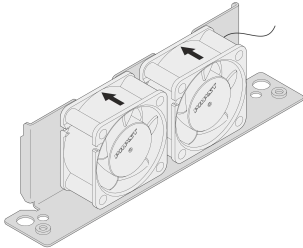

## FEATURES

Fan holder for mounting on bottom of case

Fans are simple to fit to the fan holder using vibration-damping fixing material

Fan holders fix into desktop case with 2 plastic feet or into 19" case with 2 screws

Fan holder cannot be used in conjunction with the mounting plate (instead use mounting plate with integrated fan holder)

For technical data of fans, please see delivery includes

## SPECIFICATIONS

**Finish:** Aluminum-Zinc Plated

**Type:** Fan Tray

**Product Type:** Fan Unit

**Input Voltage DC:** 12V min

Table 1/2

Catalog Number	Width	Depth	Package Quantity	Max Static Pressure	Max Ambient Temperature	Airflow
24828-104	40mm	20mm	1		70°C	10m <sup>3</sup> /h
24828-105	40mm	20mm	1		70°C	10m <sup>3</sup> /h
24828-107	40mm	20mm	1		70°C	10m <sup>3</sup> /h

CatalogNumber	Width	Depth	Package Quantity	Max Static Pressure	Max Ambient Temperature	Airflow
24828-204	80mm	25mm	1		70°C	19m³/h
24828-205	80mm	25mm	1		70°C	19m³/h
24828-207	80mm	25mm	1		70°C	19m³/h
24828-305	119mm	25mm	1		70°C	170m³/h
24828-307	119mm	25mm	1		70°C	170m³/h
24830-101	80mm	25mm	1	95.41Pa	70°C	109m³/h
24830-102	80mm	25mm	1			

Table 2/2

Catalog Number	Noise Level	Height	Material	Power	Product Family	Quick Ship
24828-104	18dB(A)	40mm	Steel	0.9W	Interscale	No
24828-105	18dB(A)	40mm	Steel	0.9W	Interscale	No
24828-107	18dB(A)	40mm	Steel	0.9W	Interscale	No
24828-204	32dB(A)	80mm	Steel	2W	Interscale	No
24828-205	32dB(A)	80mm	Steel	2W	Interscale	No
24828-207	32dB(A)	80mm	Steel	2W	Interscale	No
24828-305	43dB(A)	119mm	Steel	5.3W	Interscale	No
24828-307	43dB(A)	119mm	Steel	5.3W	Interscale	No
24830-101	44.62dB(A)	80mm	Steel			No

CatalogNumber	Noise Level	Height	Material	Power	Product Family	Quick Ship
24830-102		80mm	Steel			No

## WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

### North America

All locations  
+1.763.422.2661  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

### Europe

Straubenhardt, Germany  
+49.7082.794.0  
Betschdorf, France  
+33.3.88.90.64.90  
Warsaw, Poland  
+48.22.209.98.35  
Assago, Italy  
+39.02.932.7141  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

### Asia

Shanghai, China  
+86.21.2412.6943  
Qingdao, China  
+86.532.8771.6101  
Singapore  
+65.6768.5800  
Shin-Yokohama, Japan  
+81.45.476.0271  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

### Middle East & India

Dubai, United Arab Emirates  
+971.4.378.1700  
Bangalore, India  
+91.80.6715.2001  
Istanbul, Turkey  
+90.216.250.7374  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)



Our powerful portfolio of brands:

**CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE**