


# Joint Bond T6 Complete Welder Pair, Signal

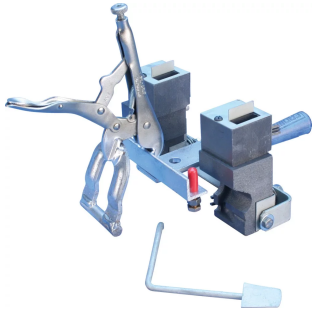

## FEATURES

Complete welder assembly provides a convenient means of attaching jumper bonds to the head of the rail, across the joint

Connection is made within the confines of the splice bar

Includes mold cleaner

## SPECIFICATIONS

**Rail Type:** 85 lb to 141 lb T-Rail Sections

**Material:** Steel;Graphite;Thermoplastic

Table 1/1

Catalog Number	Article Number	Bond Terminal Style	Conductor Size	Conductor Outer Diameter, Nominal	Bond Length	Welder Style
SBHFT6A		Head Free	3/16" Bondstrand	4.76mm	165.1mm	T6
SBHFT6C		Head Free	3/16" Bondstrand	4.76mm	190.5mm	T6
SBHFT6D		Head Free	3/16" Bondstrand	4.76mm	247.7mm	T6
SBTBT6A		1" Tab	3/16" Bondstrand	4.76mm	165.1mm	T6
SBTBT6C		3/4" Tab	3/16" Bondstrand	4.76mm	190.5mm	T6

CatalogNumber	Article Number	Bond Terminal Style	Conductor Size	Conductor OuterDiameter, Nominal	Bond Length	Welder Style
SBTBT6D	715408	1" Tab	3/16" Bondstrand	4.76mm	247.7mm	T6
SBXST6A		3/4" XS	3/16" Bondstrand	4.76mm	165.1mm	T6
SBXST6C	165570	3/4" XS	3/16" Bondstrand	4.76mm	190.5mm	T6
SBXST6D		3/4" XS	3/16" Bondstrand	4.76mm	247.7mm	T6
SBST6X2	222628	1" Tab	35 mm <sup>2</sup> Ropelay	7.75mm	177.8mm	T6
SBHFT6B		Head Free	5/16" Bondstrand	7.95mm	177.8mm	T6
SBTBT6B		1" Tab	5/16" Bondstrand	0.79mm	177.8mm	T6
SBTBT6E		1" Tab	5/16" Bondstrand	0.79mm	247.7mm	T6

## WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

⚠ WARNING: This product can expose you to chemicals including diisononyl phthalate, which is known to the State of California to cause cancer. For more information go to [www.P65Warnings.ca.gov](http://www.P65Warnings.ca.gov).

### North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

### Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

### Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

### APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Our powerful portfolio of brands:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE