

# Replacement Module for DSD, 60 kA



## CERTIFICATIONS




## SPECIFICATIONS

Catalog Number	DSD1601SR150M
Article Number	702455
Nominal System Voltage (Un)	110 - 120 V
Max Continuous Operating Voltage (Uc)	150 VAC 200 VDC
Nominal Discharge Current (In), Per Mode	25kA 8/20 $\mu$ s
Max Discharge Current (Imax), Per Mode	60kA 8/20 $\mu$ s
Voltage Protection Level (Up)	1000 V @ 25 kA
Impulse Current (Iimp)	5kA 10/350 $\mu$ s
Frequency	0 - 60 Hz
Short Circuit Current Rating (SCCR)	25kA
Technology	MOV with thermal disconnect
Enclosure Material	UL® 94V-0 Thermoplastic
Status Indication	Mechanical flag

Catalog Number	DSD1601SR150M
Temperature	-40 to 80 °C
Module Width	1 M
Depth (D)	48mm
Height (H)	45 mm
Width (W)	18 mm
Unit Weight	0.05 kg

DIAGRAMS

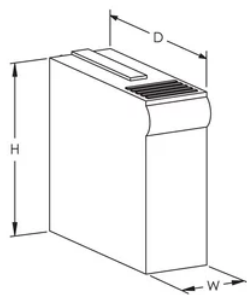

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221  
Option 1 – Customer Care  
Option 2 – Technical  
Support

Europe

Netherlands:  
+31 800-0200135  
France:  
+33 800 901 793

Europe

Germany:  
800 1890272  
Other Countries:  
+31 13 5835404

APAC

Shanghai:  
+ 86 21 2412 1618/19  
Sydney:  
+61 2 9751 8500



Our powerful portfolio of brands:

CADDY   ERICO   HOFFMAN   ILSCO   SCHROFF   TRACHTE