

# Through Wall/Roof Connector



## CERTIFICATIONS



## FEATURES

- Can be used with air terminals or threaded rod
- Positive bolt tension cable clamping for conductors
- Includes washer and nut for secure connections

## SPECIFICATIONS

Table 1/1


| Catalog Number | Material | Finish | Thread Size (TS) | Width (W) | Unit Weight | Depth (D) |
|----------------|----------|--------|------------------|-----------|-------------|-----------|
| LPA61058       | Aluminum | Bare   | 5/8" UNC         | 46.74 mm  | 0.07 kg     | 36.07mm   |
| LPA61012       | Aluminum | Bare   | 1/2" UNC         | 46.74 mm  | 0.07 kg     | 36.07mm   |
| LPC61038       | Bronze   | Bare   | 3/8" UNC         | 46.74 mm  | 0.17 kg     | 36.07mm   |

| CatalogNumber | Material                                                      | Finish | Thread Size (TS) | Width (W) | Unit Weight | Depth (D) |
|---------------|---------------------------------------------------------------|--------|------------------|-----------|-------------|-----------|
| LPC610BI58    | Aluminum,<br>Bronze,<br>Stainless Steel<br>304 (EN<br>1.4301) | Bare   | 5/8" UNC         | 46.74 mm  | 0.17 kg     | 36.07mm   |
| LPC61012      | Bronze                                                        | Bare   | 1/2" UNC         | 46.74 mm  | 0.17 kg     | 36.07mm   |
| LPC610BI38    | Aluminum,<br>Bronze,<br>Stainless Steel<br>304 (EN<br>1.4301) | Bare   | 3/8" UNC         | 46.74 mm  | 0.17 kg     | 36.07mm   |
| LPC61058      | Bronze                                                        | Bare   | 5/8" UNC         | 46.74 mm  | 0.17 kg     | 36.07mm   |
| LPC610BI12    | Aluminum,<br>Bronze,<br>Stainless Steel<br>304 (EN<br>1.4301) | Bare   | 1/2" UNC         | 46.74 mm  | 0.17 kg     | 36.07mm   |
| LPC610L12     | Bronze                                                        | Tinned | 1/2" UNC         | 46.74 mm  | 0.17 kg     | 36.07mm   |

## ADDITIONAL PRODUCT DETAILS

Stainless steel separator included with LPC610BI parts for bi-metallic applications.

## DIAGRAMS

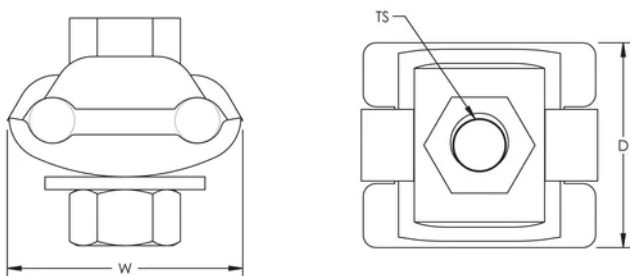

## WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.



WARNING: This product can expose you to chemicals including lead, which is known to the State of California to cause cancer and birth defects or other reproductive harm. For more information go to [www.P65Warnings.ca.gov](http://www.P65Warnings.ca.gov).

**North America**

+1.800.753.9221  
Option 1 – Customer Care  
Option 2 – Technical  
Support

**Europe**

Netherlands:  
+31 800-0200135  
France:  
+33 800 901 793

**Europe**

Germany:  
800 1890272  
Other Countries:  
+31 13 5835404

**APAC**

Shanghai:  
+ 86 21 2412 1618/19  
Sydney:  
+61 2 9751 8500



Our powerful portfolio of brands:

**CADDY   ERICO   HOFFMAN   ILSCO   SCHROFF   TRACHTE**