


Panhead Screw, Torx

Power Utilities

Panhead screws.

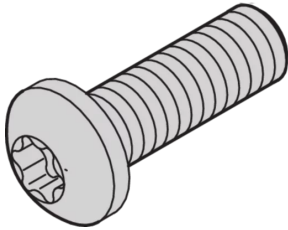

CERTIFICATIONS



FEATURES

Panhead screw

SPECIFICATIONS

Table 1/2

Catalog Number	Length	Finish	Package Quantity	Thread Size	Material	Product Family
24560-148	10 mm	Nickel Plated	100	M2.5	Steel	
24560-147	7 mm	Nickel Plated	100	M2.5	Steel	EuropacPRO, RatiopacPRO, RatiopacPRO AIR, CompacPRO, PropacPRO, MultipacPRO
24560-161	12 mm	Nickel Plated	100	M2.5	Steel	

CatalogNumber	Length	Finish	Package Quantity	Thread Size	Material	Product Family
24560-135	6 mm	Zinc Plated	100	M4	Steel	EuropacPRO
24560-178	6 mm	Nickel Plated	100	M2.5	Steel	EuropacPRO, RatiopacPRO, RatiopacPRO AIR, CompacPRO, PropacPRO, MultipacPRO
24560-162	14 mm	Nickel Plated	100	M2.5	Steel	
24560-163	16 mm	Nickel Plated	100	M2.5	Steel	

Table 2/2

Catalog Number	Product Type	Type	Works With	Torque
24560-148	Screw	Panhead Screw	Backplanes, Test Adapters	0.3 N·m
24560-147	Screw	Panhead Screw	Front Panels, Eurorack, Novastar, Varistar, Varistar CP	0.3 N·m
24560-161	Screw	Panhead Screw	Backplanes, Test Adapters	0.3 N·m
24560-135	Screw	Panhead Screw	Subracks	1.3 N·m
24560-178	Screw	Panhead Screw	Front Panels, Eurorack, Novastar, Varistar, Varistar CP	
24560-162	Screw	Panhead Screw	Backplanes, Test Adapters	
24560-163	Screw	Panhead Screw	Backplanes, Test Adapters	

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE