


# Front Panel, U-shaped, Screwless Mounting for RatiopacPRO Style, Retrofit Shielding

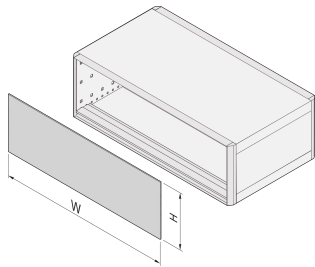

Front panel screwless, front side: anodized, rear side: conductive; unshielded

## CERTIFICATIONS



## FEATURES

Front panel, Al, 2.5 mm, front: anodized, rear: conductive; unshielded

Enables screwless mounting on horizontal rails

## SPECIFICATIONS

- Material:** Aluminum
- Finish:** Anodized; Passivated
- Works With:** Cases
- Product Type:** Front Panel
- Type:** Front Panel
- Product Family:** RatiopacPRO Style; RatiopacPRO

Table 1/1

Catalog Number	Rack Height	Rack Width	Package Quantity	Height	Width	Quick Ship
34572-199	2U	28HP	1	84mm	141.9mm	No

CatalogNumber	Rack Height	Rack Width	Package Quantity	Height	Width	Quick Ship
34572-203	3U	28HP	1	128.4mm	141.9mm	No
34572-200	2U	42HP	1	84mm	213.2mm	No
34572-207	4U	28HP	1	172.9mm	141.9mm	No
34572-201	2U	63HP	1	84mm	319.7mm	No
34572-204	3U	42HP	1	128.4mm	213.2mm	No
34572-202	2U	84HP	1	84mm	426.4mm	No
34572-208	4U	42HP	1	172.9mm	213.2mm	No
34572-205	3U	63HP	1	128.4mm	319.7mm	No
34572-206	3U	84HP	1	128.4mm	426.4mm	No
34572-209	4U	63HP	1	172.9mm	319.7mm	No
34572-210	4U	84HP	1	172.9mm	426.4mm	No
34572-225	6U	63HP	1	261.8mm	319.7mm	No
34572-226	6U	84HP	1	261.8mm	426.4mm	No
34572-223	6U	28HP	1	261.8mm	141.9mm	No
34572-224	6U	42HP	1	261.8mm	213.2mm	No

## WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

### North America

All locations

+1.763.422.2661

Chat with us:

[nvent.com/schroff](https://nvent.com/schroff)

### Europe

Straubenhardt, Germany

+49.7082.794.0

Betschdorf, France

+33.3.88.90.64.90

Warsaw, Poland

+48.22.209.98.35

Assago, Italy

+39.02.932.7141

Chat with us:

[nvent.com/schroff](https://nvent.com/schroff)

### Asia

Shanghai, China

+86.21.2412.6943

Qingdao, China

+86.532.8771.6101

Singapore

+65.6768.5800

Shin-Yokohama, Japan

+81.45.476.0271

Chat with us:

[nvent.com/schroff](https://nvent.com/schroff)

### Middle East & India

Dubai, United Arab

Emirates

+971.4.378.1700

Bangalore, India

+91.80.6715.2001

Istanbul, Turkey

+90.216.250.7374

Chat with us:

[nvent.com/schroff](https://nvent.com/schroff)



Our powerful portfolio of brands:

**CADDY**

**ERICO**

**HOFFMAN**

**ILSCO**

**SCHROFF**

**TRACHTE**