


# PropacPRO Case Design Elements

To individualize the PropacPRO case design. The elements will be screwed from the rear side of the die cast frame.

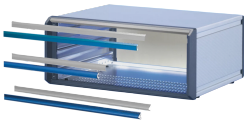

## CERTIFICATIONS



## FEATURES

To individualize the case design

Available in 3 forms and two colors

## SPECIFICATIONS

|                        |                |
|------------------------|----------------|
| <b>Material:</b>       | Aluminum       |
| <b>Finish:</b>         | Anodized       |
| <b>Works With:</b>     | Cases          |
| <b>Product Type:</b>   | Corner Profile |
| <b>Product Family:</b> | PropacPRO      |

Table 1/1

| Catalog Number | Rack Width | Type    | Color Code | Color          | Quick Ship |
|----------------|------------|---------|------------|----------------|------------|
| 20850-299      | 42HP       | Rounded | RAL 5007   | Brilliant Blue | No         |
| 20850-184      | 42HP       | Rounded | RAL 7035   | Light Grey     | No         |

| Catalog Number | Rack Width | Type     | Color Code | Color          | Quick Ship |
|----------------|------------|----------|------------|----------------|------------|
| 20850-190      | 42HP       | Squared  | RAL 7035   | Light Grey     | No         |
| 20850-196      | 42HP       | Triangle | RAL 7035   | Light Grey     | No         |
| 20850-315      | 42HP       | Squared  | RAL 5007   | Brilliant Blue | No         |
| 20850-331      | 42HP       | Triangle | RAL 5007   | Brilliant Blue | No         |
| 20850-300      | 63HP       | Rounded  | RAL 5007   | Brilliant Blue | No         |
| 20850-185      | 63HP       | Rounded  | RAL 7035   | Light Grey     | No         |
| 20850-191      | 63HP       | Squared  | RAL 7035   | Light Grey     | No         |
| 20850-197      | 63HP       | Triangle | RAL 7035   | Light Grey     | No         |
| 20850-316      | 63HP       | Squared  | RAL 5007   | Brilliant Blue | No         |
| 20850-332      | 63HP       | Triangle | RAL 5007   | Brilliant Blue | No         |
| 20850-301      | 84HP       | Rounded  | RAL 5007   | Brilliant Blue | No         |
| 20850-186      | 84HP       | Rounded  | RAL 7035   | Light Grey     | No         |
| 20850-192      | 84HP       | Squared  | RAL 7035   | Light Grey     | No         |
| 20850-198      | 84HP       | Triangle | RAL 7035   | Light Grey     | No         |
| 20850-317      | 84HP       | Squared  | RAL 5007   | Brilliant Blue | No         |
| 20850-333      | 84HP       | Triangle | RAL 5007   | Brilliant Blue | No         |

## ADDITIONAL PRODUCT DETAILS

Size 28 HP and further colors available on request.

Cannot be combined with front hood.

**WARNING**

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

**North America**

All locations  
+1.763.422.2661  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

**Europe**

Straubenhardt, Germany  
+49.7082.794.0  
Betschdorf, France  
+33.3.88.90.64.90  
Warsaw, Poland  
+48.22.209.98.35  
Assago, Italy  
+39.02.932.7141  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

**Asia**

Shanghai, China  
+86.21.2412.6943  
Qingdao, China  
+86.532.8771.6101  
Singapore  
+65.6768.5800  
Shin-Yokohama, Japan  
+81.45.476.0271  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

**Middle East & India**

Dubai, United Arab Emirates  
+971.4.378.1700  
Bangalore, India  
+91.80.6715.2001  
Istanbul, Turkey  
+90.216.250.7374  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)



Our powerful portfolio of brands:

**CADDY   ERICO   HOFFMAN   ILSCO   SCHROFF   TRACHTE**