

112 Loop Hanger with Flared Edges



CERTIFICATIONS



FEATURES

For steel and CPVC pipe

Flared edges help to protect plastic pipe

An integral fold-over washer (pipe sizes 2 1/2" to 8")

SPECIFICATIONS

Finish: Electrogalvanized

Material: Steel

Table 1/2

Catalog Number	Article Number	NB/DN	Outer Diameter (OD)	Rod Size (RS)	A	B
112M0050EG	297860	15	21.3 mm	M10	70.7 mm	29.2 mm
112M0100EG	297880	25	26.9 mm	M10	83.8 mm	36.2 mm
112M0125EG	297890	32	42.4 mm	M10	92.1 mm	40.2 mm


CatalogNumber	Article Number	NB/DN	Outer Diameter (OD)	Rod Size (RS)	A	B
112M0150EG	297900	40	48.3 mm	M10	98.2 mm	43.2 mm
112M0200EG	297910	50	60.3 mm	M10	110.2 mm	49.2 mm
112M0075EG	297870	20	26.9 mm	M10	76.4 mm	32.2 mm
112M0250EG	297920	65	76.1 mm	M10	138.2 mm	70.2 mm
112M0300EG	297930	80	88.9 mm	M10	154.1 mm	78.2 mm
112M0400EG	297940	100	114.3 mm	M10	193.8 mm	105.2 mm
112M0600EG	297960	150	165 mm	M12	262.7 mm	138.9 mm
112M0500EG	297950	125	141 mm	M12	236.2 mm	125.9 mm
112M0800EG	297970	200	219.1 mm	M12	337.6 mm	187.9 mm

Table 2/2

Catalog Number	Article Number	C	Static Load	Certifications
112M0050EG	297860	26.2 mm	1330N	cUL, UL
112M0100EG	297880	27.1 mm	1330N	cUL, UL, FM Approved, Pipe Hanger Components
112M0125EG	297890	26.7 mm	1330N	UL, FM Approved, Pipe Hanger Components, cUL
112M0150EG	297900	26.7 mm	1330N	UL, FM Approved, Pipe Hanger Components, cUL
112M0200EG	297910	26.7 mm	1330N	cUL, UL, FM Approved, Pipe Hanger Components
112M0075EG	297870	26.5 mm	1330N	UL, FM Approved, Pipe Hanger Components, cUL

Catalog Number	Article Number	C	Static Load	Certifications
112M0250EG	297920	41.3 mm	2340N	UL, FM Approved, Pipe Hanger Components, cUL
112M0300EG	297930	41.4 mm	2340N	cUL, UL, FM Approved, Pipe Hanger Components
112M0400EG	297940	55.7 mm	2890N	UL, FM Approved, Pipe Hanger Components, cUL
112M0600EG	297960	64.9 mm	4450N	cUL, UL, FM Approved, Pipe Hanger Components
112M0500EG	297950	65.4 mm	2890N	UL, FM Approved, Pipe Hanger Components, cUL
112M0800EG	297970	88.5 mm	6000N	UL, FM Approved, Pipe Hanger Components, cUL

DIAGRAMS

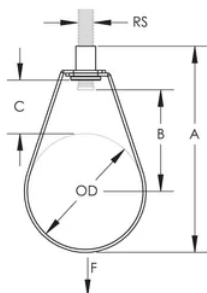

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Our powerful portfolio of brands:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE

