

USC Universal Strut Clamp for Pipe/Conduit



FEATURES

Consists of two clamps, nut and bolt

Fits into open side of strut channel

Conforms with Manufacturers Standardization Society (MSS) SP-58 (Type 59)

SPECIFICATIONS

Finish: Electrogalvanized

Material: Steel


Table 1/1

Catalog Number	Article Number	Outer Diameter (OD)	NB/DN	Width (W)	Thickness (T)	Static Load
USC017EG	712033	16.5 - 17.8 mm	10	32 mm	1.5 mm	2000N
USC020EG	712040	17.9 - 20 mm		32 mm	1.5 mm	2000N
USC013EG	712020	12.7 - 13.7 mm		32 mm	1.5 mm	2000N
USC026EG	712065	25.4 - 26.9 mm	20	32 mm	1.5 mm	2000N
USC022EG	712050	21.5 - 22.2 mm		32 mm	1.5 mm	2000N

CatalogNumber	Article Number	Outer Diameter (OD)	NB/DN	Width (W)	Thickness (T)	Static Load
USC031EG	712080	29.5 - 32 mm		32 mm	1.5 mm	2000N
USC028EG	712070	27.9 - 28.9 mm		32 mm	1.5 mm	2000N
USC036EG	712090	33.7 - 38.1 mm	25	32 mm	2 mm	2670N
USC042EG	712105	41.3 - 42.4 mm	32	32 mm	2 mm	2670N
USC046EG	712110	43 - 45 mm		32 mm	2 mm	2670N
USC048EG	712115	47.6 - 50 mm	40	32 mm	2 mm	2670N
USC053EG	712120	50.3 - 53.7 mm		32 mm	2.5 mm	3780N
USC054EG	712125	54 - 55 mm		32 mm	2.5 mm	3780N
USC058EG	712130	55.8 - 57.2 mm		32 mm	2.5 mm	3780N
USC060EG	712035	59.5 - 62.2 mm	50	32 mm	2.5 mm	3780N
USC063EG	712140	62.3 - 64.5 mm		32 mm	2.5 mm	3780N
USC068EG	712150	66 - 69 mm		32 mm	2.5 mm	3780N
USC073EG	712160	69.9 - 73 mm		32 mm	2.5 mm	3780N
USC076EG	712165	75.3 - 76.2 mm	65	32 mm	2.5 mm	3780N
USC080EG	712170	77.2 - 82.6 mm		32 mm	2.5 mm	3780N
USC086EG	712180	84.0 - 88.9 mm	80	32 mm	2.5 mm	3780N
USC101EG	712200	98.4 - 102.6 mm	90	32 mm	2.5 mm	3780N
USC113EG	712220	111.1 - 115.3 mm	100	32 mm	2.5 mm	3780N

CatalogNumber	Article Number	Outer Diameter (OD)	NB/DN	Width (W)	Thickness (T)	Static Load
USC121EG	712230	117.5 - 123.8 mm		32 mm	2.5 mm	3780N
USC129EG	712240	127.0 - 130.2 mm		32 mm	2.5 mm	3780N
USC143EG	712260	139.7 - 146.1 mm	125	32 mm	3 mm	4000N
USC159EG	712280	155.6 - 162 mm		32 mm	3 mm	4000N
USC168EG	712290	165.1 - 171.5 mm	150	32 mm	3 mm	4000N
USC218EG	712340	215.9 - 219.1 mm	200	32 mm	3 mm	4000N

DIAGRAMS

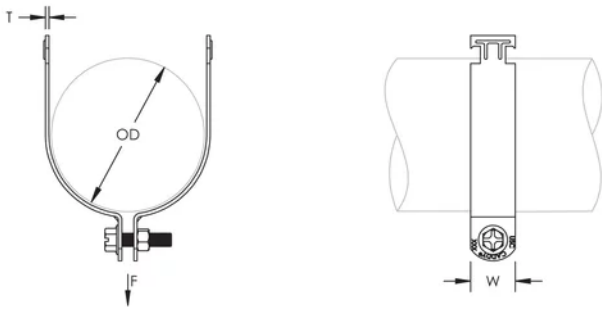

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Our powerful portfolio of brands:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE

