

# Air Terminal Base, Pipe Mount Bonding, Imperial Thread



## CERTIFICATIONS



## FEATURES

Mounts air terminal to horizontal pipe or vertical pipe using Right Angle Extension Adaptor


## SPECIFICATIONS

Table 1/2						
Catalog Number	Material	Finish	Thread Size (TS)	Outer Diameter (OD)	Depth (D)	Width (W)
LPA37212	Aluminum		1/2" UNC	38.1 - 63.5 mm	41.4mm	92 mm
LPA37258	Aluminum		5/8" UNC	38.1 - 63.5 mm	41.4mm	92 mm
LPC37212	Copper		1/2" UNC	38.1 - 63.5 mm	41.4mm	92 mm
LPC37238	Copper		3/8" UNC	38.1 - 63.5 mm	41.4mm	92 mm

CatalogNumber	Material	Finish	Thread Size (TS)	Outer Diameter (OD)	Depth (D)	Width (W)
LPC37258	Copper		5/8" UNC	38.1 - 63.5 mm	41.4mm	92 mm
LPC372L12	Copper	Tinned	1/2" UNC	38.1 - 63.5 mm	41.4mm	92 mm
LPC372L38	Copper	Tinned	3/8" UNC	38.1 - 63.5 mm	41.4mm	92 mm
LPC372L58	Copper	Tinned	5/8" UNC	38.1 - 63.5 mm	41.4mm	92 mm

Table 2/2		
Catalog Number	Unit Weight	Certifications
LPA37212	0.15 kg	E202878-Combined_CoC, E202878-Combined_CoC
LPA37258	0.15 kg	E202878-Combined_CoC, E202878-Combined_CoC
LPC37212	0.35 kg	
LPC37238	0.35 kg	
LPC37258	0.35 kg	
LPC372L12	0.35 kg	
LPC372L38	0.35 kg	
LPC372L58	0.35 kg	

DIAGRAMS

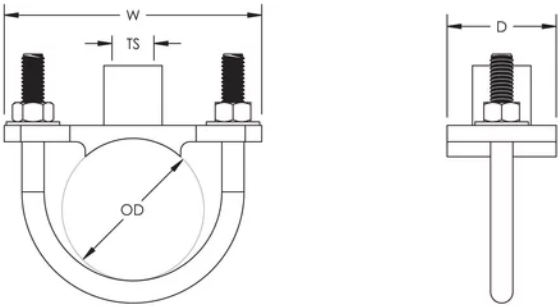

**WARNING**

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

**⚠ WARNING:** This product can expose you to chemicals including lead, which is known to the State of California to cause cancer and birth defects or other reproductive harm. For more information go to [www.P65Warnings.ca.gov](http://www.P65Warnings.ca.gov).

**North America**

+1.800.753.9221  
Option 1 – Customer Care  
Option 2 – Technical  
Support

**Europe**

Netherlands:  
+31 800-0200135  
France:  
+33 800 901 793

**Europe**

Germany:  
800 1890272  
Other Countries:  
+31 13 5835404

**APAC**

Shanghai:  
+ 86 21 2412 1618/19  
Sydney:  
+61 2 9751 8500



Our powerful portfolio of brands:

**CADDY   ERICO   HOFFMAN   ILSCO   SCHROFF   TRACHTE**