

Data Equipment Protector, 300 A 8/20 μ s Nominal Discharge Current (In), DB25, Male/Female

CATALOG NUMBER

DEPRS2322525D



FEATURES

Models to cover RS-232, RS-423, RS-422 and RS-485 protocols

Designed to provide both line to signal-ground and signal-ground to protective-earth protection

Plug-in protection is simple to install

PRODUCT ATTRIBUTES

Nominal Discharge Current (In): 0.3kA 8/20 μ s

Max Continuous Operating Voltage (Uc): 15 VDC

Capacitance: 30 pF Max

Protection Modes: All pins to ground

Connection Type: DB25, Male/Female


Depth (D): 61mm

Height (H): 16.6 mm

Width (W): 53.5 mm

Unit Weight: 0.08 kg

DIAGRAMS

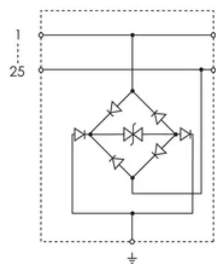

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical
Support

Europe

Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europe

Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC

Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE