

nVent ERICO Railclips, Hammer-On, 2 Conductors, Conduit Below



FEATURES

"Hammer-on" design

Securely holds conductors, reducing maintenance and improving wayside safety

Quick and easy hammer-on installation

Fits various rail profiles

Does not require removal of the ballast material

Multi-layer proprietary coating provides optimal corrosion protection

SPECIFICATIONS

Rail Type: 85 lb to 141 lb T-Rail Sections

Finish: Multi-Layer Proprietary Coating


Material: Spring Steel

Table 1/1

Catalog Number	Length (L)	Width (W)	Rail Foot Thickness (RFT)	Diameter 1 (Ø1)	Diameter 2 (Ø2)
SBA2510B	42.67mm	50.8 mm	13.21 mm	9.53 mm	12.7 mm
SBA2511B	42.67mm	50.8 mm	13.21 mm	9.53 mm	19.05 mm
SBA2512B	42.67mm	50.8 mm	13.21 mm	9.53 mm	25.4 mm

Catalog Number	Length (L)	Width (W)	Rail Foot Thickness (RFT)	Diameter 1 (Ø1)	Diameter 2 (Ø2)
SBA2512C	42.67mm	50.8 mm	13.21 mm	9.53 mm	50.8 mm

DIAGRAMS

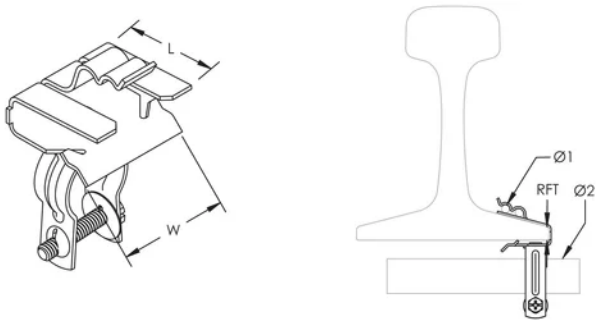

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221
 Option 1 – Customer Care
 Option 2 – Technical Support

Europe

Netherlands:
 +31 800-0200135
 France:
 +33 800 901 793

Europe

Germany:
 800 1890272
 Other Countries:
 +31 13 5835404

APAC

Shanghai:
 + 86 21 2412 1618/19
 Sydney:
 +61 2 9751 8500



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE