


Door Contact Switch Without Cable

CATALOG NUMBER

20118-810

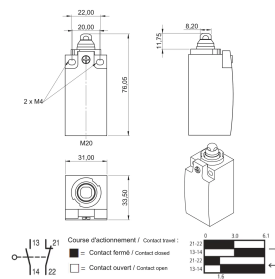

Door contact switch with magnetic contact, allows operational efficiency. This product is easy handleable by plug and play.

CERTIFICATIONS



FEATURES

Door contact switch (without connection cable)

PRODUCT ATTRIBUTES

Product Type: Switch

Depth: 33.5mm

Height: 76.5mm

Operating Temperature: -25 to 75°C

Protection Rating: IP66

Width: 31mm

Complies With: UL® 508; EN 50047 form B

Current Rating: 3 – 6A

Gross Weight: 0.1kg

Package Quantity: 1

Voltage: 24 – 230V

Wire Size: 0.5 – 2.5mm²

ADDITIONAL PRODUCT DETAILS

Please order bracket for installation of door switch (Varistar, Novastar, Eurorack) separately.

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab
Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Our powerful portfolio of brands:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE