


HF Frame Type Plug-In Unit Slide Nut, M2.5; 100 pieces

CATALOG NUMBER

21100-112

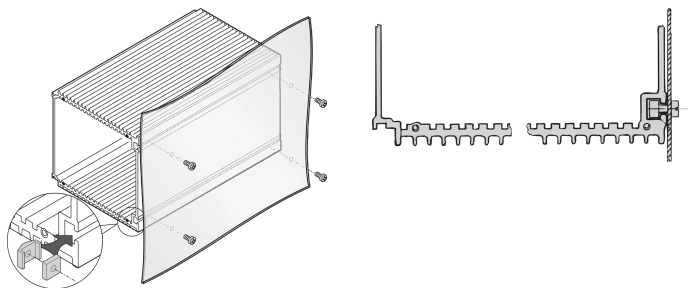

The slide nut can be inserted into the grooves of the HF tube and enable a user to assemble the tube.

CERTIFICATIONS



FEATURES

Alternative for threaded insert

PRODUCT ATTRIBUTES

Package Quantity: 100

Depth (D): 5.5mm

Finish: Zinc Plated

Height (H): 12mm

Material: Steel; Polyamide 6

Product Type: Nut

Type: Slide Nut

Width (W): 7mm


Works With: Frame Type Plug-In Unit

Net Weight: 0.079kg

Thread Size (TS): M2.5

Thread Type: Metric

DIAGRAMS

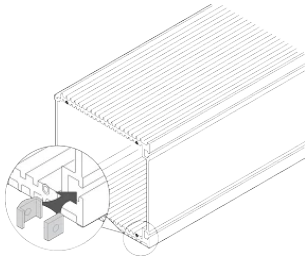

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab
Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Our powerful portfolio of brands:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE