


Novastar Raised Top Cover, Load-Carrying Capacity 50 kg, 553W 600D

CATALOG NUMBER

25230-038

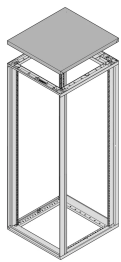

Raised top cover for better ventilation and heat escape.
Novastar raised top cover is robust and not dismountable from the outside.

CERTIFICATIONS



FEATURES

Raised Top cover (31 mm) with all-round air gap of 10 mm

Top cover attached from the inside (no screws on the outside)

Suitable for placing heavy parts on the top cover

Incl. grounding

Robust version, load-carrying capacity 50 kg

PRODUCT ATTRIBUTES

Depth: 600mm

Package Quantity: 1

Color: Black Grey

Color Code: RAL 7021

Finish: Powder Coated

Material: Steel

Product Family: Novastar

Product Type: Cabinet/Rack Top Cover

Type: Raised

Width: 553mm

Net Weight: 5.069kg

ADDITIONAL PRODUCT DETAILS

Please order lifting eye separately if required.

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab
Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Our powerful portfolio of brands:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE