

# nVent CADDY Pyramid RL Fixed Roller Support



## CERTIFICATIONS



## FEATURES

Roller-based support designed specifically for rooftop applications

Roller capability allows longitudinal movement of pipe, resulting from thermal expansion or contraction

Polymeric rollers ensure corrosion free rotation

Foam bottom offers low abrasion interface for better roof membrane protection

Compatible with roof surfaces including single ply, bituminous, metal and spray foam

Ready to use out of the box, saving installation time and labor

Hot-dip galvanized and UV stabilized for long lasting performance

## SPECIFICATIONS

|                                   |                                  |
|-----------------------------------|----------------------------------|
| <b>Static Load Safety Factor:</b> | 3:1                              |
| <b>Finish:</b>                    | Hot-Dip Galvanized               |
| <b>Material:</b>                  | Polyethylene;Polypropylene;Steel |
| <b>Temperature:</b>               | -45 to 65 °C                     |


Table 1/2

| Catalog Number | Article Number | NB/DN | Height (H) | Length (L) | Width (W) | A |
|----------------|----------------|-------|------------|------------|-----------|---|
|----------------|----------------|-------|------------|------------|-----------|---|

|      |        |         |        |         |        |        |
|------|--------|---------|--------|---------|--------|--------|
| PRF2 | 360470 | 50 Max  | 147 mm | 203mm   | 152 mm | 114 mm |
| PRF3 | 360471 | 80 Max  | 159 mm | 317.5mm | 203 mm | 159 mm |
| PRF6 | 360472 | 150 Max | 159 mm | 483mm   | 203 mm | 260 mm |

| Table 2/2      |                |              |             |             |                |
|----------------|----------------|--------------|-------------|-------------|----------------|
| Catalog Number | Article Number | Surface Area | Unit Weight | Static Load | Certifications |
| PRF2           | 360470         | 26452mm²     | 0.5 kg      | 440N        | ITB            |
| PRF3           | 360471         | 59355mm²     | 1 kg        | 1112N       |                |
| PRF6           | 360472         | 91613mm²     | 1.5 kg      | 2670N       | ITB            |

### DIAGRAMS

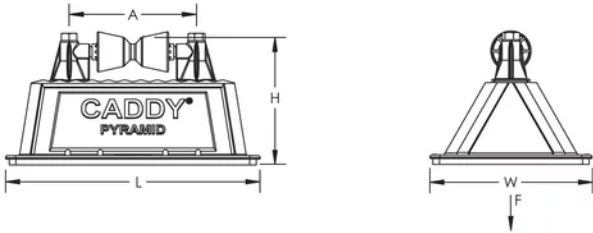

### WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

#### North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

#### Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

#### Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

#### APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Our powerful portfolio of brands:

**CADDY**

**ERICO**

**HOFFMAN**

**ILSCO**

**SCHROFF**

**TRACHTE**

