

Binding Post Lug



FEATURES

Tin plated for corrosion prevention

Annealed copper eases the crimping operation

SPECIFICATIONS


Table 1/2

Catalog Number	Material	Finish	Length (L)	Width (W)	Hole Size (HS)	Conductor Size
A2412J	Copper	Tinned	36mm	12 mm	6.5 mm	3/16" Stranded

Table 2/2

Catalog Number	Tool/Die Type
A2412J	SBT031DJ Manual Compression Tool/No die required

DIAGRAMS

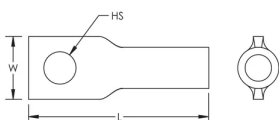

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical
Support

Europe

Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europe

Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC

Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE