

PFF Parallel Plastic Screw-In Plug for P13/P14 Couplers, Worldwide Design



FEATURES

Designed for use with the P13/P14 coupler families

Designed to keep dirt, water and concrete slurry out of the coupler during the concrete pour

Durable mounting plates allow for easy attachment to forms

Color coded for the appropriate coupler size

SPECIFICATIONS

Material: High Density Polyethylene (HDPE);Steel


Design Version: Worldwide (Globally Available Materials)

Table 1/1

Catalog Number	Rebar Size, Metric	Rebar Size, US	Rebar Size, Canada	Diameter (Ø)	Height (H)	Color
EL12PFFN	12 mm	#4	10M	65 mm	17 mm	Red
EL28PFFN	28 mm	#9	30M	95 mm	20 mm	Black
EL40PFFN	40 mm			95 mm	20 mm	Green
EL20PFFN	20 mm	#6	20M	75 mm	20 mm	Yellow

CatalogNumber	Rebar Size, Metric	Rebar Size, US	Rebar Size, Canada	Diameter (Ø)	Height (H)	Color
EL36PFFN	36 mm	#11	35M	95 mm	20 mm	Blue
EL22PFFN	22 mm	#7		95 mm	20 mm	Blue
EL16PFFN	16 mm	#5	15M	65 mm	20 mm	Black
EL32PFFN	32 mm	#10		95 mm	20 mm	Yellow
EL25PFFN	25 mm	#8	25M	95 mm	20 mm	Red

DIAGRAMS

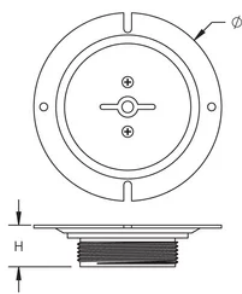

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221
 Option 1 – Customer Care
 Option 2 – Technical Support

Europe

Netherlands:
 +31 800-0200135
 France:
 +33 800 901 793

Europe

Germany:
 800 1890272
 Other Countries:
 +31 13 5835404

APAC

Shanghai:
 + 86 21 2412 1618/19
 Sydney:
 +61 2 9751 8500



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE