

CPP Tapered Plastic Screw-In Plug for A12, A22 and A32K



FEATURES

Designed for use with the A12, A22 and A32K coupler families

Designed to keep dirt, water and concrete slurry out of the coupler during the concrete pour

Color coded for the appropriate coupler size

SPECIFICATIONS

Material: High Density Polyethylene (HDPE)

Table 1/2

Catalog Number	Article Number	Rebar Size, Metric	Rebar Size, US	Rebar Size, Canada	Diameter (Ø)	Height (H)
EL16CPPB100	153090	16 mm	#5	15M	22 mm	13 mm
EL14CPPB100	153080	14 mm			22 mm	13 mm
EL10CPPB100	153060	10 mm	#3		17 mm	13 mm
EL18CPPB100	153100	18 mm			27 mm	13 mm
EL12CPPB100	153070	12 mm	#4	10M	17 mm	13 mm


CatalogNumber	Article Number	Rebar Size, Metric	Rebar Size, US	Rebar Size, Canada	Diameter (Ø)	Height (H)
EL20CPPB100	153110	20 mm	#6	20M	27 mm	13 mm
EL25CPPB100	153130	25 mm	#8	25M	33 mm	16 mm
EL36CPPB50	153180	36 mm	#11	35M	46 mm	16 mm
EL32CPPB100	153160	32 mm	#10		42 mm	16 mm
EL30CPPB100	153150	30 mm			37 mm	16 mm
EL40CPPB50	153200	40 mm			52 mm	16 mm
EL28CPPB100	153140	28 mm	#9	30M	37 mm	16 mm
EL22CPPB100	153120	22 mm	#7		33 mm	16 mm
EL50CPPB40	153220	50 mm			64 mm	16 mm

Table 2/2

Catalog Number	Article Number	Color	Package Quantity
EL16CPPB100	153090	Black	100
EL14CPPB100	153080	Green	100
EL10CPPB100	153060	Yellow	100
EL18CPPB100	153100	White	100
EL12CPPB100	153070	Red	100
EL20CPPB100	153110	Yellow	100
EL25CPPB100	153130	Red	100
EL36CPPB50	153180	Blue	50

Catalog Number	Article Number	Color	Package Quantity
EL32CPPB100	153160	Yellow	100
EL30CPPB100	153150	White	100
EL40CPPB50	153200	Green	50
EL28CPPB100	153140	Black	100
EL22CPPB100	153120	Blue	100
EL50CPPB40	153220	Black	40

DIAGRAMS

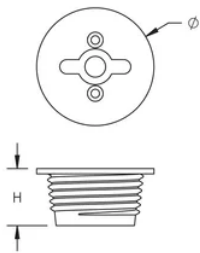

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Our powerful portfolio of brands:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE