

# Front Panel EMC Stainless Steel Shielding Kit, for U-Shaped front panels



The stainless EMC gaskets are inserted into a slot on the right hand side of the U-shaped front panels.

The gasket will be clipped onto the right front panel bracket, the 19" bracket or rear profile of the subrack

## FEATURES

The stainless steel EMC-gasket for SCHROFF U-shaped front panels, offers excellent performance in shielding effectiveness and an enormous temperature range from -200 to +160°C.

Easy mounting by clipping the gasket onto the right front panel bracket, the 19" bracket or rear profile of the subrack

Temperature range from -200 to +160°C.

## SPECIFICATIONS

|                        |                                                                              |
|------------------------|------------------------------------------------------------------------------|
| <b>Works With:</b>     | Subracks; Cases; Front Panels                                                |
| <b>Product Family:</b> | EuropacPRO; RatiopacPRO; RatiopacPRO AIR; PropacPRO; Frame Type Plug-In Unit |
| <b>Product Type:</b>   | Shielding Kit                                                                |
| <b>Material:</b>       | Stainless Steel                                                              |

Table 1/1


| Catalog Number | Rack Height | Package Quantity | Rack Width | Quick Ship |
|----------------|-------------|------------------|------------|------------|
|----------------|-------------|------------------|------------|------------|

|           |    |     |       |    |
|-----------|----|-----|-------|----|
| 21102-115 | 2U | 10  | 10HP  | No |
| 21102-105 | 3U | 10  |       | No |
| 21102-106 | 3U | 100 | 100HP | No |
| 21102-113 | 4U | 10  | 10HP  | No |
| 21102-117 | 5U | 10  | 10HP  | No |
| 21102-107 | 6U | 10  | 10HP  | No |
| 21102-108 | 6U | 100 | 100HP | No |
| 21102-109 | 9U | 10  | 10HP  | No |

## ADDITIONAL PRODUCT DETAILS

EMC gaskets (stainless) are required for shielding the front panels.

## DIAGRAMS

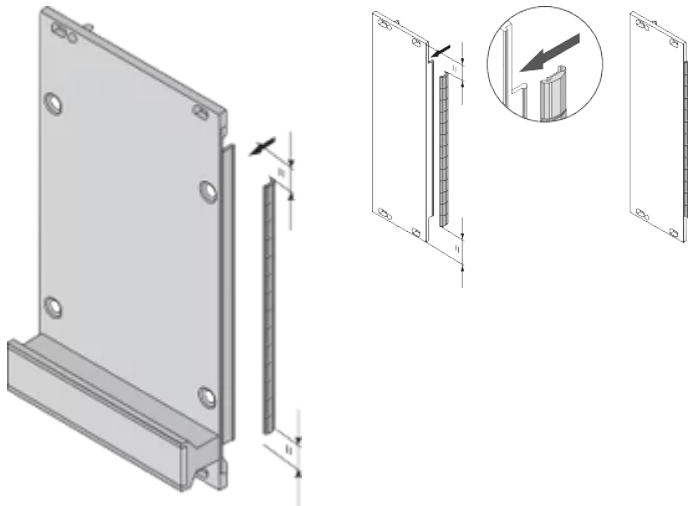

## WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

### North America

All locations  
+1.763.422.2661  
Chat with us:  
[nvent.com/schroff](https://nvent.com/schroff)

### Europe

Straubenhardt, Germany  
+49.7082.794.0  
Betschdorf, France  
+33.3.88.90.64.90  
Warsaw, Poland  
+48.22.209.98.35  
Assago, Italy  
+39.02.932.7141  
Chat with us:  
[nvent.com/schroff](https://nvent.com/schroff)

### Asia

Shanghai, China  
+86.21.2412.6943  
Qingdao, China  
+86.532.8771.6101  
Singapore  
+65.6768.5800  
Shin-Yokohama, Japan  
+81.45.476.0271  
Chat with us:  
[nvent.com/schroff](https://nvent.com/schroff)

### Middle East & India

Dubai, United Arab Emirates  
+971.4.378.1700  
Bangalore, India  
+91.80.6715.2001  
Istanbul, Turkey  
+90.216.250.7374  
Chat with us:  
[nvent.com/schroff](https://nvent.com/schroff)



Our powerful portfolio of brands:

**CADDY   ERICO   HOFFMAN   ILSCO   SCHROFF   TRACHTE**