


# Z-Rail for Connector, EN 60603-2, DIN 41612

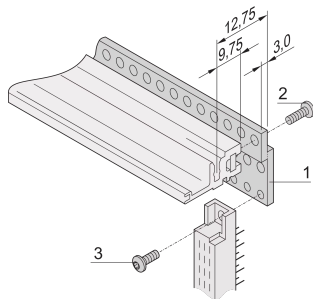

Z-rail for connector in accordance with EN 60603-2 (DIN 41612).

## CERTIFICATIONS



## FEATURES

Aluminum extrusion, anodized

Z-rails are bolted to the subrack for connector mounting (rear horizontal rail type ST, threaded insert inserted, insulation strip)

For connectors to EN 60603-2 (DIN 41612)

## SPECIFICATIONS

|                        |                                                                |
|------------------------|----------------------------------------------------------------|
| <b>Material:</b>       | Aluminum                                                       |
| <b>Finish:</b>         | Anodized                                                       |
| <b>Works With:</b>     | Subracks; Cases                                                |
| <b>Product Family:</b> | EuropacPRO; RatiopacPRO; RatiopacPRO AIR; CompacPRO; PropacPRO |
| <b>Product Type:</b>   | Z-Rail                                                         |

Table 1/1

| Catalog Number | Rack Width | Package Quantity | Length  | Quick Ship |
|----------------|------------|------------------|---------|------------|
| 30822-025      | 20HP       | 1                | 101.6mm | No         |

| Catalog Number | Rack Width | Package Quantity | Length  | Quick Ship |
|----------------|------------|------------------|---------|------------|
| 30822-045      | 40HP       | 1                | 203.2mm | No         |

## ADDITIONAL PRODUCT DETAILS

For attaching the z-rail to the horizontal rail, both a threaded insert and Torx panhead screw are required; please order these separately.

## WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

### North America

All locations  
+1.763.422.2661  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

### Europe

Straubenhardt, Germany  
+49.7082.794.0  
Betschdorf, France  
+33.3.88.90.64.90  
Warsaw, Poland  
+48.22.209.98.35  
Assago, Italy  
+39.02.932.7141  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

### Asia

Shanghai, China  
+86.21.2412.6943  
Qingdao, China  
+86.532.8771.6101  
Singapore  
+65.6768.5800  
Shin-Yokohama, Japan  
+81.45.476.0271  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

### Middle East & India

Dubai, United Arab Emirates  
+971.4.378.1700  
Bangalore, India  
+91.80.6715.2001  
Istanbul, Turkey  
+90.216.250.7374  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)



Our powerful portfolio of brands:

**CADDY   ERICO   HOFFMAN   ILSCO   SCHROFF   TRACHTE**