

# PEMSA Wire Basket Tray L Bracket



## CERTIFICATIONS



## FEATURES

Easy to use, quick connect feature

Ideal for typical wall and channel installations

IEC 61537 load rating and earthing compliant

## SPECIFICATIONS

**Finish:** Electrogalvanized


**Material:** Steel

Table 1/1

Catalog Number	Article Number	Length (L)	Width (W)	Height (H)	Static Load	Certifications
WBT100LBRKT	820200	170mm	54 mm	138 mm	588N	DoP, CADDY EU WBT, ANOR EU WTB B S, CE, CADDY EU WBT BRT

CatalogNumber	Article Number	Length (L)	Width (W)	Height (H)	Static Load	Certifications
WBT150LBRKT	820210	220mm	54 mm	138 mm	588N	ANOR EU WTB B S, CE, CADDY EU WBT BRT, DoP, CADDY EU WBT
WBT200LBRKT	820220	270mm	54 mm	138 mm	588N	
WBT300LBRKT	820230	370mm	54 mm	138 mm	373N	ANOR EU WTB B S, DoP, CADDY EU WBT, CE, CADDY EU WBT BRT, UKCA, CADDY EU WBT B
WBT400LBRKT	820240	470mm	54 mm	138 mm	275N	DoP, CADDY EU WBT, CE, CADDY EU WBT BRT, UKCA, CADDY EU WBT B, ANOR EU WTB B S

## DIAGRAMS

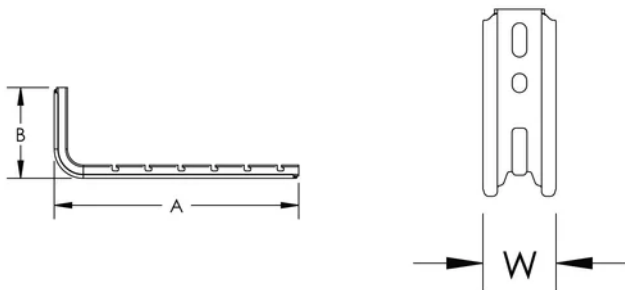

## WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

#### North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

#### Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

#### Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

#### APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Our powerful portfolio of brands:

**CADDY**

**ERICO**

**HOFFMAN**

**ILSCO**

**SCHROFF**

**TRACHTE**

