

PEMSA Wire Basket Tray Universal Tray Splice



CERTIFICATIONS



FEATURES

Significant mechanical joint strength

Robust steel design and construction

IEC 61537 load rating and earthing compliant

SPECIFICATIONS


Table 1/2

Catalog Number	Article Number	Material	Color	Finish	A	B
WBTUNVSPLBG	820701	Steel	Black	Electrogalvanized	24.5 mm	23 mm
WBTUNVSPLEG	820700	Steel		Electrogalvanized	24.5 mm	23 mm
WBTUNVSPLS4	820702	Stainless Steel 304 (EN 1.4301)			24.5 mm	23 mm

Table 2/2

Catalog Number	Article Number	Rod Size (RS)	Certifications
WBTUNVSPLBG	820701	6	CE, CADDY EU WBT UNV, ANOR EU WTB EG S4 BG, DoP, CADDY EU WBT
WBTUNVSPLEG	820700	6	ANOR EU WTB EG S4 BG, DoP, CADDY EU WBT, CE, CADDY EU WBT UNV
WBTUNVSPLS4	820702	6	UKCA, CADDY WBTUNVSPLS4, CE, CADDY WBTUNVSPLS4

DIAGRAMS

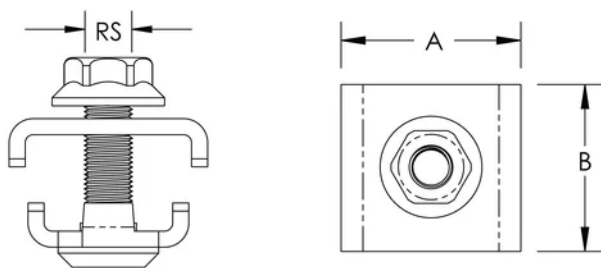

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical Support

Europe

Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europe

Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC

Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE

