

# PEMSA Wire Basket Tray

## Data Solutions



The PEMS A Wire Basket Tray is the backbone of PEMS A Wire Basket Tray System. Highly engineered features help ensure a secure installation that complies with industry codes and standards for high-performance cables. Clever design allows the installer to maximize field efficiency with the Rejiband Rapide Integrated Splice.

### CERTIFICATIONS



### FEATURES

Provides optimal support for high-performance low voltage and data cables

Innovative Rejiband Rapide installation system

IEC 61537 load rating and earthing compliant

Responsive design and layout services, including seismic

### SPECIFICATIONS

Table 1/2

| Catalog Number | Article Number | Color | Material                        | Finish        | Length (L) | Height (H) |
|----------------|----------------|-------|---------------------------------|---------------|------------|------------|
| WBT35X60S4     | 821003         |       | Stainless Steel 304 (EN 1.4301) |               | 3000mm     | 35mm       |
| WBT35X60BA     | 821001         | Black | Carbon Steel                    | Powder Coated | 3000mm     | 35mm       |

| CatalogNumber | Article Number | Color | Material                        | Finish             | Length (L) | Height (H) |
|---------------|----------------|-------|---------------------------------|--------------------|------------|------------|
| WBT35X60EG    | 821000         |       | Carbon Steel                    | Electrogalvaniz ed | 3000mm     | 35mm       |
| WBT35X100BA   | 821011         | Black | Carbon Steel                    | Powder Coated      | 3000mm     | 35mm       |
| WBT35X100EG   | 821010         |       | Carbon Steel                    | Electrogalvaniz ed | 3000mm     | 35mm       |
| WBT35X100S4   | 821013         |       | Stainless Steel 304 (EN 1.4301) |                    | 3000mm     | 35mm       |
| WBT35X150BA   | 821021         | Black | Carbon Steel                    | Powder Coated      | 3000mm     | 35mm       |
| WBT35X150EG   | 821020         |       | Carbon Steel                    | Electrogalvaniz ed | 3000mm     | 35mm       |
| WBT35X150S4   | 821023         |       | Stainless Steel 304 (EN 1.4301) |                    | 3000mm     | 35mm       |
| WBT35X200BA   | 821031         | Black | Carbon Steel                    | Powder Coated      | 3000mm     | 35mm       |
| WBT35X200EG   | 821030         |       | Carbon Steel                    | Electrogalvaniz ed | 3000mm     | 35mm       |
| WBT35X200S4   | 821033         |       | Stainless Steel 304 (EN 1.4301) |                    | 3000mm     | 35mm       |
| WBT35X300BA   | 821041         | Black | Carbon Steel                    | Powder Coated      | 3000mm     | 35mm       |
| WBT35X300EG   | 821040         |       | Carbon Steel                    | Electrogalvaniz ed | 3000mm     | 35mm       |
| WBT35X300S4   | 821043         |       | Stainless Steel 304 (EN 1.4301) |                    | 3000mm     | 35mm       |
| WBT35X400BA   | 821051         | Black | Carbon Steel                    | Powder Coated      | 3000mm     | 35mm       |
| WBT35X400EG   | 821050         |       | Carbon Steel                    | Electrogalvaniz ed | 3000mm     | 35mm       |
| WBT35X400S4   | 821053         |       | Stainless Steel 304 (EN 1.4301) |                    | 3000mm     | 35mm       |
| WBT60X60BA    | 820001         | Black | Carbon Steel                    | Powder Coated      | 3000mm     | 60mm       |

| CatalogNumber | Article Number | Color | Material                              | Finish                | Length (L) | Height (H) |
|---------------|----------------|-------|---------------------------------------|-----------------------|------------|------------|
| WBT60X60BG    | 820002         | Black | Carbon Steel                          | Electrogalvaniz<br>ed | 3000mm     | 60mm       |
| WBT60X60EG    | 820000         |       | Carbon Steel                          | Electrogalvaniz<br>ed | 3000mm     | 60mm       |
| WBT60X60S4    | 820003         |       | Stainless Steel<br>304 (EN<br>1.4301) |                       | 3000mm     | 60mm       |
| WBT60X100BA   | 820011         | Black | Carbon Steel                          | Powder Coated         | 3000mm     | 60mm       |
| WBT60X100BG   | 820012         | Black | Carbon Steel                          | Electrogalvaniz<br>ed | 3000mm     | 60mm       |
| WBT60X100EG   | 820010         |       | Carbon Steel                          | Electrogalvaniz<br>ed | 3000mm     | 60mm       |
| WBT60X100S4   | 820013         |       | Stainless Steel<br>304 (EN<br>1.4301) |                       | 3000mm     | 60mm       |
| WBT60X150BA   | 820021         | Black | Carbon Steel                          | Powder Coated         | 3000mm     | 60mm       |
| WBT60X150BG   | 820022         | Black | Carbon Steel                          | Electrogalvaniz<br>ed | 3000mm     | 60mm       |
| WBT60X150EG   | 820020         |       | Carbon Steel                          | Electrogalvaniz<br>ed | 3000mm     | 60mm       |
| WBT60X150S4   | 820023         |       | Stainless Steel<br>304 (EN<br>1.4301) |                       | 3000mm     | 60mm       |
| WBT60X200BA   | 820031         | Black | Carbon Steel                          | Powder Coated         | 3000mm     | 60mm       |
| WBT60X200BG   | 820032         | Black | Carbon Steel                          | Electrogalvaniz<br>ed | 3000mm     | 60mm       |
| WBT60X200EG   | 820030         |       | Carbon Steel                          | Electrogalvaniz<br>ed | 3000mm     | 60mm       |
| WBT60X200S4   | 820033         |       | Stainless Steel<br>304 (EN<br>1.4301) |                       | 3000mm     | 60mm       |
| WBT60X300BA   | 820041         | Black | Carbon Steel                          | Powder Coated         | 3000mm     | 60mm       |
| WBT60X300BG   | 820042         | Black | Carbon Steel                          | Electrogalvaniz<br>ed | 3000mm     | 60mm       |

| CatalogNumber | Article Number | Color | Material                              | Finish                | Length (L) | Height (H) |
|---------------|----------------|-------|---------------------------------------|-----------------------|------------|------------|
| WBT60X300EG   | 820040         |       | Carbon Steel                          | Electrogalvaniz<br>ed | 3000mm     | 60mm       |
| WBT60X300S4   | 820043         |       | Stainless Steel<br>304 (EN<br>1.4301) |                       | 3000mm     | 60mm       |
| WBT60X400BA   | 820051         | Black | Carbon Steel                          | Powder Coated         | 3000mm     | 60mm       |
| WBT60X400BG   | 820052         | Black | Carbon Steel                          | Electrogalvaniz<br>ed | 3000mm     | 60mm       |
| WBT60X400EG   | 820050         |       | Carbon Steel                          | Electrogalvaniz<br>ed | 3000mm     | 60mm       |
| WBT60X400S4   | 820053         |       | Stainless Steel<br>304 (EN<br>1.4301) |                       | 3000mm     | 60mm       |
| WBT60X450BA   | 820081         | Black | Carbon Steel                          | Powder Coated         | 3000mm     | 60mm       |
| WBT60X450BG   | 820082         | Black | Carbon Steel                          | Electrogalvaniz<br>ed | 3000mm     | 60mm       |
| WBT60X450EG   | 820080         |       | Carbon Steel                          | Electrogalvaniz<br>ed | 3000mm     | 60mm       |
| WBT60X450S4   | 820083         |       | Stainless Steel<br>304 (EN<br>1.4301) |                       | 3000mm     | 60mm       |
| WBT60X500BA   | 820061         | Black | Carbon Steel                          | Powder Coated         | 3000mm     | 60mm       |
| WBT60X500BG   | 820062         | Black | Carbon Steel                          | Electrogalvaniz<br>ed | 3000mm     | 60mm       |
| WBT60X500EG   | 820060         |       | Carbon Steel                          | Electrogalvaniz<br>ed | 3000mm     | 60mm       |
| WBT60X500S4   | 820063         |       | Stainless Steel<br>304 (EN<br>1.4301) |                       | 3000mm     | 60mm       |
| WBT60X600BA   | 820075         | Black | Carbon Steel                          | Powder Coated         | 3000mm     | 60mm       |
| WBT60X600BG   | 820076         | Black | Carbon Steel                          | Electrogalvaniz<br>ed | 3000mm     | 60mm       |
| WBT60X600EG   | 820074         |       | Carbon Steel                          | Electrogalvaniz<br>ed | 3000mm     | 60mm       |

| CatalogNumber    | Article Number | Color | Material                              | Finish                | Length (L) | Height (H) |
|------------------|----------------|-------|---------------------------------------|-----------------------|------------|------------|
| WBT60X600S4      | 820077         |       | Stainless Steel<br>304 (EN<br>1.4301) |                       | 3000mm     | 60mm       |
| WBT100X100B<br>A | 823011         | Black | Carbon Steel                          | Powder Coated         | 3000mm     | 100mm      |
| WBT100X100B<br>G | 823012         | Black | Carbon Steel                          | Electrogalvaniz<br>ed | 3000mm     | 100mm      |
| WBT100X100E<br>G | 823010         |       | Carbon Steel                          | Electrogalvaniz<br>ed | 3000mm     | 100mm      |
| WBT100X100S<br>4 | 823013         |       | Stainless Steel<br>304 (EN<br>1.4301) |                       | 3000mm     | 100mm      |
| WBT100X150B<br>A | 823021         | Black | Carbon Steel                          | Powder Coated         | 3000mm     | 100mm      |
| WBT100X150B<br>G | 823022         | Black | Carbon Steel                          | Electrogalvaniz<br>ed | 3000mm     | 100mm      |
| WBT100X150E<br>G | 823020         |       | Carbon Steel                          | Electrogalvaniz<br>ed | 3000mm     | 100mm      |
| WBT100X150S<br>4 | 823023         |       | Stainless Steel<br>304 (EN<br>1.4301) |                       | 3000mm     | 100mm      |
| WBT100X200B<br>A | 823031         | Black | Carbon Steel                          | Powder Coated         | 3000mm     | 100mm      |
| WBT100X200B<br>G | 823032         | Black | Carbon Steel                          | Electrogalvaniz<br>ed | 3000mm     | 100mm      |
| WBT100X200E<br>G | 823030         |       | Carbon Steel                          | Electrogalvaniz<br>ed | 3000mm     | 100mm      |
| WBT100X200S<br>4 | 823033         |       | Stainless Steel<br>304 (EN<br>1.4301) |                       | 3000mm     | 100mm      |

| CatalogNumber    | Article Number | Color | Material                              | Finish                | Length (L) | Height (H) |
|------------------|----------------|-------|---------------------------------------|-----------------------|------------|------------|
| WBT100X300B<br>A | 823041         | Black | Carbon Steel                          | Powder Coated         | 3000mm     | 100mm      |
| WBT100X300B<br>G | 823042         | Black | Carbon Steel                          | Electrogalvaniz<br>ed | 3000mm     | 100mm      |
| WBT100X300E<br>G | 823040         |       | Carbon Steel                          | Electrogalvaniz<br>ed | 3000mm     | 100mm      |
| WBT100X300S<br>4 | 823043         |       | Stainless Steel<br>304 (EN<br>1.4301) |                       | 3000mm     | 100mm      |
| WBT100X400B<br>A | 823051         | Black | Carbon Steel                          | Powder Coated         | 3000mm     | 100mm      |
| WBT100X400B<br>G | 823052         | Black | Carbon Steel                          | Electrogalvaniz<br>ed | 3000mm     | 100mm      |
| WBT100X400E<br>G | 823050         |       | Carbon Steel                          | Electrogalvaniz<br>ed | 3000mm     | 100mm      |
| WBT100X400S<br>4 | 823053         |       | Stainless Steel<br>304 (EN<br>1.4301) |                       | 3000mm     | 100mm      |
| WBT100X450B<br>A | 823081         | Black | Carbon Steel                          | Powder Coated         | 3000mm     | 100mm      |
| WBT100X450B<br>G | 823082         | Black | Carbon Steel                          | Electrogalvaniz<br>ed | 3000mm     | 100mm      |
| WBT100X450E<br>G | 823080         |       | Carbon Steel                          | Electrogalvaniz<br>ed | 3000mm     | 100mm      |
| WBT100X450S<br>4 | 823083         |       | Stainless Steel<br>304 (EN<br>1.4301) |                       | 3000mm     | 100mm      |
| WBT100X500B<br>A | 823061         | Black | Carbon Steel                          | Powder Coated         | 3000mm     | 100mm      |

| CatalogNumber    | Article Number | Color | Material                              | Finish                | Length (L) | Height (H) |
|------------------|----------------|-------|---------------------------------------|-----------------------|------------|------------|
| WBT100X500B<br>G | 823062         | Black | Carbon Steel                          | Electrogalvaniz<br>ed | 3000mm     | 100mm      |
| WBT100X500E<br>G | 823060         |       | Carbon Steel                          | Electrogalvaniz<br>ed | 3000mm     | 100mm      |
| WBT100X500S<br>4 | 823063         |       | Stainless Steel<br>304 (EN<br>1.4301) |                       | 3000mm     | 100mm      |
| WBT100X600B<br>A | 823071         | Black | Carbon Steel                          | Powder Coated         | 3000mm     | 100mm      |
| WBT100X600B<br>G | 823072         | Black | Carbon Steel                          | Electrogalvaniz<br>ed | 3000mm     | 100mm      |
| WBT100X600E<br>G | 823070         |       | Carbon Steel                          | Electrogalvaniz<br>ed | 3000mm     | 100mm      |
| WBT100X600S<br>4 | 823073         |       | Stainless Steel<br>304 (EN<br>1.4301) |                       | 3000mm     | 100mm      |
| WBT150X200B<br>A | 825031         | Black | Carbon Steel                          | Powder Coated         | 3000mm     | 150mm      |
| WBT150X200B<br>G | 825032         | Black | Carbon Steel                          | Electrogalvaniz<br>ed | 3000mm     | 150mm      |
| WBT150X200E<br>G | 825030         |       | Carbon Steel                          | Electrogalvaniz<br>ed | 3000mm     | 150mm      |
| WBT150X200S<br>4 | 825033         |       | Stainless Steel<br>304 (EN<br>1.4301) |                       | 3000mm     | 150mm      |
| WBT150X300B<br>A | 825041         | Black | Carbon Steel                          | Powder Coated         | 3000mm     | 150mm      |
| WBT150X300B<br>G | 825042         | Black | Carbon Steel                          | Electrogalvaniz<br>ed | 3000mm     | 150mm      |

| CatalogNumber | Article Number | Color | Material                        | Finish            | Length (L) | Height (H) |
|---------------|----------------|-------|---------------------------------|-------------------|------------|------------|
| WBT150X300EG  | 825040         |       | Carbon Steel                    | Electrogalvanized | 3000mm     | 150mm      |
| WBT150X300S4  | 825043         |       | Stainless Steel 304 (EN 1.4301) |                   | 3000mm     | 150mm      |
| WBT150X400BA  | 825051         | Black | Carbon Steel                    | Powder Coated     | 3000mm     | 150mm      |
| WBT150X400BG  | 825052         | Black | Carbon Steel                    | Electrogalvanized | 3000mm     | 150mm      |
| WBT150X400EG  | 825050         |       | Carbon Steel                    | Electrogalvanized | 3000mm     | 150mm      |
| WBT150X400S4  | 825053         |       | Stainless Steel 304 (EN 1.4301) |                   | 3000mm     | 150mm      |
| WBT150X450BA  | 825081         | Black | Carbon Steel                    | Powder Coated     | 3000mm     | 150mm      |
| WBT150X450BG  | 825082         | Black | Carbon Steel                    | Electrogalvanized | 3000mm     | 150mm      |
| WBT150X450EG  | 825080         |       | Carbon Steel                    | Electrogalvanized | 3000mm     | 150mm      |
| WBT150X450S4  | 825083         |       | Stainless Steel 304 (EN 1.4301) |                   | 3000mm     | 150mm      |
| WBT150X500BA  | 825061         | Black | Carbon Steel                    | Powder Coated     | 3000mm     | 150mm      |
| WBT150X500BG  | 825062         | Black | Carbon Steel                    | Electrogalvanized | 3000mm     | 150mm      |
| WBT150X500EG  | 825060         |       | Carbon Steel                    | Electrogalvanized | 3000mm     | 150mm      |

| CatalogNumber    | Article Number | Color | Material                              | Finish                | Length (L) | Height (H) |
|------------------|----------------|-------|---------------------------------------|-----------------------|------------|------------|
| WBT150X500S<br>4 | 825063         |       | Stainless Steel<br>304 (EN<br>1.4301) |                       | 3000mm     | 150mm      |
| WBT150X600B<br>A | 825071         | Black | Carbon Steel                          | Powder Coated         | 3000mm     | 150mm      |
| WBT150X600B<br>G | 825072         | Black | Carbon Steel                          | Electrogalvaniz<br>ed | 3000mm     | 150mm      |
| WBT150X600E<br>G | 825070         |       | Carbon Steel                          | Electrogalvaniz<br>ed | 3000mm     | 150mm      |
| WBT150X600S<br>4 | 825073         |       | Stainless Steel<br>304 (EN<br>1.4301) |                       | 3000mm     | 150mm      |
| WBT150X900B<br>A | 825091         | Black | Carbon Steel                          | Powder Coated         | 3000mm     | 150mm      |
| WBT150X900B<br>G | 825092         | Black | Carbon Steel                          | Electrogalvaniz<br>ed | 3000mm     | 150mm      |
| WBT150X900E<br>G | 825090         |       | Carbon Steel                          | Electrogalvaniz<br>ed | 3000mm     | 150mm      |
| WBT150X900S<br>4 | 825093         |       | Stainless Steel<br>304 (EN<br>1.4301) |                       | 3000mm     | 150mm      |

Table 2/2

| Catalog Number | Article Number | Width (W) | Unit Weight | Certifications                          |
|----------------|----------------|-----------|-------------|-----------------------------------------|
| WBT35X60S4     | 821003         | 60mm      | 1.19kg      | CE, CADDY EU WBT,<br>UKCA, CADDY EU WBT |
| WBT35X60BA     | 821001         | 60mm      | 1.2kg       |                                         |
| WBT35X60EG     | 821000         | 60mm      | 1.2kg       | UKCA, CADDY EU WBT,<br>CE, CADDY EU WBT |
| WBT35X100BA    | 821011         | 100mm     | 1.62kg      |                                         |

| Catalog Number | Article Number | Width (W) | Unit Weight | Certifications                                                      |
|----------------|----------------|-----------|-------------|---------------------------------------------------------------------|
| WBT35X100EG    | 821010         | 100mm     | 1.62kg      | ANOR EU WTB EG S4<br>BG, UKCA, CADDY EU<br>WBT, CE, CADDY EU<br>WBT |
| WBT35X100S4    | 821013         | 100mm     | 1.61kg      | CE, CADDY EU WBT,<br>UKCA, CADDY EU WBT                             |
| WBT35X150BA    | 821021         | 150mm     | 1.76kg      |                                                                     |
| WBT35X150EG    | 821020         | 150mm     | 1.76kg      | UKCA, CADDY EU WBT,<br>ANOR EU WTB EG S4<br>BG, CE, CADDY EU<br>WBT |
| WBT35X150S4    | 821023         | 150mm     | 2.12kg      | UKCA, CADDY EU WBT,<br>CE, CADDY EU WBT                             |
| WBT35X200BA    | 821031         | 200mm     | 2.5kg       |                                                                     |
| WBT35X200EG    | 821030         | 200mm     | 2.5kg       | ANOR EU WTB EG S4<br>BG, UKCA, CADDY EU<br>WBT, CE, CADDY EU<br>WBT |
| WBT35X200S4    | 821033         | 200mm     | 3.04kg      | UKCA, CADDY EU WBT,<br>CE, CADDY EU WBT,<br>ANOR EU WTB EG S4<br>BG |
| WBT35X300BA    | 821041         | 300mm     | 3.42kg      |                                                                     |
| WBT35X300EG    | 821040         | 300mm     | 3.42kg      | CE, CADDY EU WBT,<br>ANOR EU WTB EG S4<br>BG, UKCA, CADDY EU<br>WBT |
| WBT35X300S4    | 821043         | 300mm     | 4.13kg      | ANOR EU WTB EG S4<br>BG, UKCA, CADDY EU<br>WBT, CE, CADDY EU<br>WBT |
| WBT35X400BA    | 821051         | 400mm     | 4.29kg      |                                                                     |
| WBT35X400EG    | 821050         | 400mm     | 4.29kg      | UKCA, CADDY EU WBT,<br>CE, CADDY EU WBT,<br>ANOR EU WTB EG S4<br>BG |

| Catalog Number | Article Number | Width (W) | Unit Weight | Certifications                                                                            |
|----------------|----------------|-----------|-------------|-------------------------------------------------------------------------------------------|
| WBT35X400S4    | 821053         | 400mm     | 5.22kg      | ANOR EU WTB EG S4<br>BG, UKCA, CADDY EU<br>WBT, CE, CADDY EU<br>WBT                       |
| WBT60X60BA     | 820001         | 60mm      | 2.32kg      |                                                                                           |
| WBT60X60BG     | 820002         | 60mm      | 2.32kg      | ANOR EU WTB EG S4<br>BG, UKCA, CADDY EU<br>WBT, CE, CADDY EU<br>WBT                       |
| WBT60X60EG     | 820000         | 60mm      | 2.32kg      | ANOR EU WTB EG S4<br>BG, UKCA, CADDY EU<br>WBT, CE, CADDY EU<br>WBT                       |
| WBT60X60S4     | 820003         | 60mm      | 2.32kg      | UKCA, CADDY EU WBT,<br>CE, CADDY EU WBT                                                   |
| WBT60X100BA    | 820011         | 100mm     | 2.43kg      |                                                                                           |
| WBT60X100BG    | 820012         | 100mm     | 2.43kg      | UKCA, CADDY EU WBT,<br>DoP, CADDY EU WBT,<br>CE, CADDY EU WBT,<br>ANOR EU WTB EG S4<br>BG |
| WBT60X100EG    | 820010         | 100mm     | 2.43kg      | UKCA, CADDY EU WBT,<br>DoP, CADDY EU WBT,<br>CE, CADDY EU WBT,<br>ANOR EU WTB EG S4<br>BG |
| WBT60X100S4    | 820013         | 100mm     | 2.43kg      | ANOR EU WTB EG S4<br>BG, CE, CADDY EU<br>WBT, DoP, CADDY EU<br>WBT, UKCA, CADDY EU<br>WBT |
| WBT60X150BA    | 820021         | 150mm     | 2.6kg       |                                                                                           |
| WBT60X150BG    | 820022         | 150mm     | 2.6kg       | DoP, CADDY EU WBT,<br>UKCA, CADDY EU WBT,<br>ANOR EU WTB EG S4<br>BG, CE, CADDY EU<br>WBT |
| WBT60X150EG    | 820020         | 150mm     | 2.6kg       | ANOR EU WTB EG S4<br>BG, CE, CADDY EU<br>WBT, DoP, CADDY EU<br>WBT, UKCA, CADDY EU<br>WBT |

| Catalog Number | Article Number | Width (W) | Unit Weight | Certifications                                                                |
|----------------|----------------|-----------|-------------|-------------------------------------------------------------------------------|
| WBT60X150S4    | 820023         | 150mm     | 2.6kg       | CE, CADDY EU WBT, DoP, CADDY EU WBT, UKCA, CADDY EU WBT, ANOR EU WTB EG S4 BG |
| WBT60X200BA    | 820031         | 200mm     | 3.33kg      |                                                                               |
| WBT60X200BG    | 820032         | 200mm     | 3.33kg      | DoP, CADDY EU WBT, UKCA, CADDY EU WBT, ANOR EU WTB EG S4 BG, CE, CADDY EU WBT |
| WBT60X200EG    | 820030         | 200mm     | 3.33kg      | CE, CADDY EU WBT, DoP, CADDY EU WBT, UKCA, CADDY EU WBT, ANOR EU WTB EG S4 BG |
| WBT60X200S4    | 820033         | 200mm     | 3.33kg      | CE, CADDY EU WBT, DoP, CADDY EU WBT, ANOR EU WTB EG S4 BG, UKCA, CADDY EU WBT |
| WBT60X300BA    | 820041         | 300mm     | 5.13kg      |                                                                               |
| WBT60X300BG    | 820042         | 300mm     | 5.13kg      | ANOR EU WTB EG S4 BG, UKCA, CADDY EU WBT, CE, CADDY EU WBT, DoP, CADDY EU WBT |
| WBT60X300EG    | 820040         | 300mm     | 5.13kg      | CE, CADDY EU WBT, DoP, CADDY EU WBT, ANOR EU WTB EG S4 BG, UKCA, CADDY EU WBT |
| WBT60X300S4    | 820043         | 300mm     | 5.13kg      | CE, CADDY EU WBT, DoP, CADDY EU WBT, ANOR EU WTB EG S4 BG, UKCA, CADDY EU WBT |
| WBT60X400BA    | 820051         | 400mm     | 6.21kg      |                                                                               |
| WBT60X400BG    | 820052         | 400mm     | 6.21kg      | UKCA, CADDY EU WBT, CE, CADDY EU WBT, DoP, CADDY EU WBT, ANOR EU WTB EG S4 BG |

| Catalog Number | Article Number | Width (W) | Unit Weight | Certifications                                                                |
|----------------|----------------|-----------|-------------|-------------------------------------------------------------------------------|
| WBT60X400EG    | 820050         | 400mm     | 6.21kg      | CE, CADDY EU WBT, DoP, CADDY EU WBT, ANOR EU WTB EG S4 BG, UKCA, CADDY EU WBT |
| WBT60X400S4    | 820053         | 400mm     | 6.21kg      | ANOR EU WTB EG S4 BG, UKCA, CADDY EU WBT, CE, CADDY EU WBT                    |
| WBT60X450BA    | 820081         | 450mm     | 6.39kg      |                                                                               |
| WBT60X450BG    | 820082         | 450mm     | 6.39kg      | UKCA, CADDY EU WBT, CE, CADDY EU WBT, ANOR EU WTB EG S4 BG                    |
| WBT60X450EG    | 820080         | 450mm     | 6.39kg      | CE, CADDY EU WBT, ANOR EU WTB EG S4 BG, DoP, CADDY EU WBT, UKCA, CADDY EU WBT |
| WBT60X450S4    | 820083         | 450mm     | 6.39kg      |                                                                               |
| WBT60X500BA    | 820061         | 500mm     | 7.35kg      |                                                                               |
| WBT60X500BG    | 820062         | 500mm     | 7.35kg      | UKCA, CADDY EU WBT, ANOR EU WTB EG S4 BG, CE, CADDY EU WBT                    |
| WBT60X500EG    | 820060         | 500mm     | 7.35kg      | UKCA, CADDY EU WBT, ANOR EU WTB EG S4 BG, CE, CADDY EU WBT                    |
| WBT60X500S4    | 820063         | 500mm     | 7.35kg      | UKCA, CADDY EU WBT, ANOR EU WTB EG S4 BG, CE, CADDY EU WBT                    |
| WBT60X600BA    | 820075         | 600mm     | 8.43kg      |                                                                               |
| WBT60X600BG    | 820076         | 600mm     | 8.43kg      | UKCA, CADDY EU WBT, ANOR EU WTB EG S4 BG, CE, CADDY EU WBT                    |

| Catalog Number | Article Number | Width (W) | Unit Weight | Certifications                                                                |
|----------------|----------------|-----------|-------------|-------------------------------------------------------------------------------|
| WBT60X600EG    | 820074         | 600mm     | 8.43kg      | UKCA, CADDY EU WBT, ANOR EU WTB EG S4 BG, CE, CADDY EU WBT                    |
| WBT60X600S4    | 820077         | 600mm     | 8.43kg      | CE, CADDY EU WBT, DoP, CADDY EU WBT, ANOR EU WTB EG S4 BG, UKCA, CADDY EU WBT |
| WBT100X100BA   | 823011         | 100mm     | 3.27kg      |                                                                               |
| WBT100X100BG   | 823012         | 100mm     | 3.27kg      | ANOR EU WTB EG S4 BG, UKCA, CADDY EU WBT, DoP, CADDY EU WBT, CE, CADDY EU WBT |
| WBT100X100EG   | 823010         | 100mm     | 3.27kg      | ANOR EU WTB EG S4 BG, UKCA, CADDY EU WBT, DoP, CADDY EU WBT, CE, CADDY EU WBT |
| WBT100X100S4   | 823013         | 100mm     | 3.27kg      | CE, CADDY EU WBT, ANOR EU WTB EG S4 BG, UKCA, CADDY EU WBT, DoP, CADDY EU WBT |
| WBT100X150BA   | 823021         | 150mm     | 3.45kg      |                                                                               |
| WBT100X150BG   | 823022         | 150mm     | 3.45kg      | ANOR EU WTB EG S4 BG, UKCA, CADDY EU WBT, DoP, CADDY EU WBT, CE, CADDY EU WBT |
| WBT100X150EG   | 823020         | 150mm     | 3.45kg      | UKCA, CADDY EU WBT, DoP, CADDY EU WBT, CE, CADDY EU WBT, ANOR EU WTB EG S4 BG |
| WBT100X150S4   | 823023         | 150mm     | 3.45kg      | CE, CADDY EU WBT, ANOR EU WTB EG S4 BG, DoP, CADDY EU WBT, UKCA, CADDY EU WBT |
| WBT100X200BA   | 823031         | 200mm     | 4.14kg      |                                                                               |


| Catalog Number | Article Number | Width (W) | Unit Weight | Certifications                                                                |
|----------------|----------------|-----------|-------------|-------------------------------------------------------------------------------|
| WBT100X200BG   | 823032         | 200mm     | 4.14kg      | DoP, CADDY EU WBT, UKCA, CADDY EU WBT, CE, CADDY EU WBT, ANOR EU WTB EG S4 BG |
| WBT100X200EG   | 823030         | 200mm     | 4.14kg      | CE, CADDY EU WBT, ANOR EU WTB EG S4 BG, DoP, CADDY EU WBT, UKCA, CADDY EU WBT |
| WBT100X200S4   | 823033         | 200mm     | 4.14kg      | CE, CADDY EU WBT, ANOR EU WTB EG S4 BG, DoP, CADDY EU WBT, UKCA, CADDY EU WBT |
| WBT100X300BA   | 823041         | 300mm     | 6.15kg      |                                                                               |
| WBT100X300BG   | 823042         | 300mm     | 6.15kg      | DoP, CADDY EU WBT, UKCA, CADDY EU WBT, CE, CADDY EU WBT, ANOR EU WTB EG S4 BG |
| WBT100X300EG   | 823040         | 300mm     | 6.15kg      | CE, CADDY EU WBT, ANOR EU WTB EG S4 BG, DoP, CADDY EU WBT, UKCA, CADDY EU WBT |
| WBT100X300S4   | 823043         | 300mm     | 6.15kg      | CE, CADDY EU WBT, DoP, CADDY EU WBT, UKCA, CADDY EU WBT, ANOR EU WTB EG S4 BG |
| WBT100X400BA   | 823051         | 400mm     | 7.23kg      |                                                                               |
| WBT100X400BG   | 823052         | 400mm     | 7.23kg      | UKCA, CADDY EU WBT, ANOR EU WTB EG S4 BG, CE, CADDY EU WBT, DoP, CADDY EU WBT |
| WBT100X400EG   | 823050         | 400mm     | 7.23kg      | ANOR EU WTB EG S4 BG, CE, CADDY EU WBT, DoP, CADDY EU WBT, UKCA, CADDY EU WBT |

| Catalog Number | Article Number | Width (W) | Unit Weight | Certifications                                                                |
|----------------|----------------|-----------|-------------|-------------------------------------------------------------------------------|
| WBT100X400S4   | 823053         | 400mm     | 7.23kg      | CE, CADDY EU WBT, DoP, CADDY EU WBT, UKCA, CADDY EU WBT, ANOR EU WTB EG S4 BG |
| WBT100X450BA   | 823081         | 450mm     | 7.44kg      |                                                                               |
| WBT100X450BG   | 823082         | 450mm     | 7.44kg      | UKCA, CADDY EU WBT, ANOR EU WTB EG S4 BG, CE, CADDY EU WBT                    |
| WBT100X450EG   | 823080         | 450mm     | 7.44kg      | CE, CADDY EU WBT, DoP, CADDY EU WBT, UKCA, CADDY EU WBT, ANOR EU WTB EG S4 BG |
| WBT100X450S4   | 823083         | 450mm     | 7.44kg      |                                                                               |
| WBT100X500BA   | 823061         | 500mm     | 8.34kg      |                                                                               |
| WBT100X500BG   | 823062         | 500mm     | 8.34kg      | ANOR EU WTB EG S4 BG, UKCA, CADDY EU WBT, CE, CADDY EU WBT                    |
| WBT100X500EG   | 823060         | 500mm     | 8.34kg      | ANOR EU WTB EG S4 BG, UKCA, CADDY EU WBT, CE, CADDY EU WBT                    |
| WBT100X500S4   | 823063         | 500mm     | 8.34kg      | UKCA, CADDY EU WBT, CE, CADDY EU WBT, ANOR EU WTB EG S4 BG                    |
| WBT100X600BA   | 823071         | 600mm     | 9.42kg      |                                                                               |
| WBT100X600BG   | 823072         | 600mm     | 9.42kg      | ANOR EU WTB EG S4 BG, UKCA, CADDY EU WBT, CE, CADDY EU WBT                    |
| WBT100X600EG   | 823070         | 600mm     | 9.42kg      | UKCA, CADDY EU WBT, CE, CADDY EU WBT, ANOR EU WTB EG S4 BG                    |

| Catalog Number | Article Number | Width (W) | Unit Weight | Certifications                                             |
|----------------|----------------|-----------|-------------|------------------------------------------------------------|
| WBT100X600S4   | 823073         | 600mm     | 9.42kg      | UKCA, CADDY EU WBT, CE, CADDY EU WBT, ANOR EU WTB EG S4 BG |
| WBT150X200BA   | 825031         | 200mm     | 6.01kg      |                                                            |
| WBT150X200BG   | 825032         | 200mm     | 6.01kg      | UKCA, CADDY EU WBT, CE, CADDY EU WBT                       |
| WBT150X200EG   | 825030         | 200mm     | 6.01kg      | UKCA, CADDY EU WBT, CE, CADDY EU WBT, DoP, CADDY EU WBT    |
| WBT150X200S4   | 825033         | 200mm     | 6.01kg      | CE, CADDY EU WBT, UKCA, CADDY EU WBT                       |
| WBT150X300BA   | 825041         | 300mm     | 7.29kg      |                                                            |
| WBT150X300BG   | 825042         | 300mm     | 7.29kg      | UKCA, CADDY EU WBT, CE, CADDY EU WBT                       |
| WBT150X300EG   | 825040         | 300mm     | 7.29kg      | CE, CADDY EU WBT, DoP, CADDY EU WBT, UKCA, CADDY EU WBT    |
| WBT150X300S4   | 825043         | 300mm     | 7.29kg      | UKCA, CADDY EU WBT, CE, CADDY EU WBT                       |
| WBT150X400BA   | 825051         | 400mm     | 8.47kg      |                                                            |
| WBT150X400BG   | 825052         | 400mm     | 8.47kg      | UKCA, CADDY EU WBT, CE, CADDY EU WBT                       |
| WBT150X400EG   | 825050         | 400mm     | 8.47kg      | CE, CADDY EU WBT, DoP, CADDY EU WBT, UKCA, CADDY EU WBT    |
| WBT150X400S4   | 825053         | 400mm     | 8.47kg      | UKCA, CADDY EU WBT, CE, CADDY EU WBT                       |
| WBT150X450BA   | 825081         | 450mm     | 8.68kg      |                                                            |
| WBT150X450BG   | 825082         | 450mm     | 8.68kg      | CE, CADDY EU WBT, UKCA, CADDY EU WBT                       |
| WBT150X450EG   | 825080         | 450mm     | 8.68kg      | UKCA, CADDY EU WBT, CE, CADDY EU WBT                       |
| WBT150X450S4   | 825083         | 450mm     | 8.68kg      | UKCA, CADDY EU WBT, CE, CADDY EU WBT                       |

| Catalog Number | Article Number | Width (W) | Unit Weight | Certifications                       |
|----------------|----------------|-----------|-------------|--------------------------------------|
| WBT150X500BA   | 825061         | 500mm     | 9.7kg       |                                      |
| WBT150X500BG   | 825062         | 500mm     | 9.7kg       | CE, CADDY EU WBT, UKCA, CADDY EU WBT |
| WBT150X500EG   | 825060         | 500mm     | 9.7kg       | UKCA, CADDY EU WBT, CE, CADDY EU WBT |
| WBT150X500S4   | 825063         | 500mm     | 9.7kg       | CE, CADDY EU WBT, UKCA, CADDY EU WBT |
| WBT150X600BA   | 825071         | 600mm     | 10.65kg     |                                      |
| WBT150X600BG   | 825072         | 600mm     | 10.65kg     | UKCA, CADDY EU WBT, CE, CADDY EU WBT |
| WBT150X600EG   | 825070         | 600mm     | 10.65kg     | UKCA, CADDY EU WBT, CE, CADDY EU WBT |
| WBT150X600S4   | 825073         | 600mm     | 10.65kg     | CE, CADDY EU WBT, UKCA, CADDY EU WBT |
| WBT150X900BA   | 825091         | 900mm     | 15.98kg     |                                      |
| WBT150X900BG   | 825092         | 900mm     | 15.98kg     |                                      |
| WBT150X900EG   | 825090         | 900mm     | 15.98kg     |                                      |
| WBT150X900S4   | 825093         | 900mm     | 15.98kg     |                                      |

## DIAGRAMS

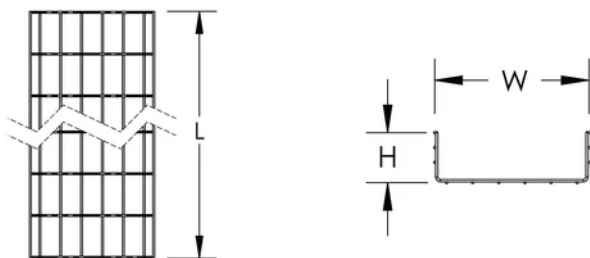

## WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause

product malfunction, property damage, serious bodily injury and death and/or void your warranty.



Our powerful portfolio of brands:

**CADDY   ERICO   HOFFMAN   ILSCO   SCHROFF   TRACHTE**