


Varistar 19" Shelf, Stationary, 75 kg

Data Solutions

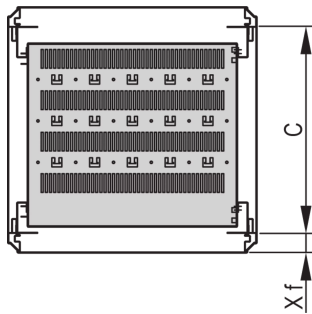

Varistar 19" Shelf, Stationary, 75 kg.

CERTIFICATIONS



FEATURES

Static load-carrying capacity 75 kg

St, 1.5 mm

Incl. GND/grounding

Width 495 mm

For mounting on four 19" panel/slide mounts

SPECIFICATIONS

Product Type: Shelf

Material: Steel

Table 1/2

Catalog Number	Width	Depth	Package Quantity	Color	Color Code	Finish
----------------	-------	-------	------------------	-------	------------	--------

22130-309	495mm		1	Light Grey	RAL 7035	Powder Coated
21130-302	495mm		1	Black Grey	RAL 7021	Powder Coated
21130-303	495mm		1	Black Grey	RAL 7021	Powder Coated
21130-304	495mm	800mm	1	Black Grey	RAL 7021	Powder Coated
21130-305	495mm	800mm	1	Black Grey	RAL 7021	Powder Coated
21130-309	495mm		1	Black Grey	RAL 7021	Powder Coated
22130-302	495mm		1	Light Grey	RAL 7035	Powder Coated
22130-303	495mm		1	Light Grey	RAL 7035	Powder Coated
22130-304	495mm	800mm	1	Light Grey	RAL 7035	Powder Coated
22130-305	495mm	800mm	1	Light Grey	RAL 7035	Powder Coated

Table 2/2			
Catalog Number	Height	Length	Type
22130-309	740mm	682mm	Full Depth
21130-302	400mm	342mm	Recessed Depth
21130-303	500mm	442mm	Full Depth
21130-304	600mm	642mm	Recessed Depth
21130-305	700mm	642mm	Full Depth
21130-309	740mm	682mm	Full Depth
22130-302	400mm	342mm	Recessed Depth
22130-303	500mm	442mm	Full Depth

Catalog Number	Height	Length	Type
22130-304	600mm	642mm	Recessed Depth
22130-305	700mm	642mm	Full Depth

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE