


## Varistar CP Mobile Base/Plinth

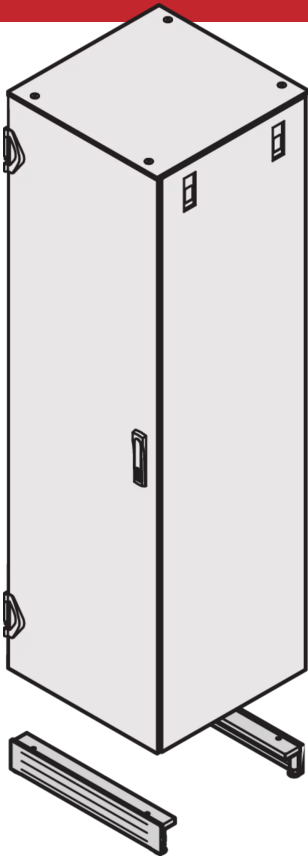

Mobile base/plinth to make a cabinet mobile.

### FEATURES

---

Covers, St, 1.5 mm

Load-carrying capacity on casters 400 kg, on adjustable feet 1600 kg

Support, St, 3 mm

Color RAL 7021

Plinth height H = 103 mm, with feet adjustable from 126 to 134 mm

### SPECIFICATIONS

---

**Product Type:** Cabinet/Rack Base

**Material:** Steel

Table 1/2

| Catalog Number | Width | Depth  | Package Quantity | Color      | Color Code | Finish        |
|----------------|-------|--------|------------------|------------|------------|---------------|
| 21630-664      | 800mm | 1000mm | 1                | Black Grey | RAL 7021   | Powder Coated |
| 21630-655      | 600mm | 600mm  | 1                | Black Grey | RAL 7021   | Powder Coated |
| 21630-663      | 800mm | 900mm  | 1                | Black Grey | RAL 7021   | Powder Coated |
| 21630-662      | 800mm | 800mm  | 1                | Black Grey | RAL 7021   | Powder Coated |
| 21630-661      | 800mm | 600mm  | 1                |            |            | Powder Coated |
| 21630-658      | 600mm | 1000mm | 1                | Black Grey | RAL 7021   | Powder Coated |
| 21630-657      | 600mm | 900mm  | 1                | Black Grey | RAL 7021   | Powder Coated |
| 21630-656      | 600mm | 800mm  | 1                | Black Grey | RAL 7021   | Powder Coated |

Table 2/2

| Catalog Number | Type                | Works With  | Quick Ship |
|----------------|---------------------|-------------|------------|
| 21630-664      | Base Plinth, Mobile | Varistar CP | No         |
| 21630-655      | Base Plinth, Mobile | Varistar CP | No         |
| 21630-663      | Base Plinth, Mobile | Varistar CP | No         |
| 21630-662      | Base Plinth, Mobile | Varistar CP | No         |
| 21630-661      | Base Plinth, Mobile | Varistar CP | No         |
| 21630-658      | Base Plinth, Mobile | Varistar CP | No         |
| 21630-657      | Base Plinth, Mobile | Varistar CP | No         |
| 21630-656      | Base Plinth, Mobile | Varistar CP | No         |

**WARNING**

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

**North America**

All locations  
+1.763.422.2661  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

**Europe**

Straubenhardt, Germany  
+49.7082.794.0  
Betschdorf, France  
+33.3.88.90.64.90  
Warsaw, Poland  
+48.22.209.98.35  
Assago, Italy  
+39.02.932.7141  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

**Asia**

Shanghai, China  
+86.21.2412.6943  
Qingdao, China  
+86.532.8771.6101  
Singapore  
+65.6768.5800  
Shin-Yokohama, Japan  
+81.45.476.0271  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

**Middle East & India**

Dubai, United Arab Emirates  
+971.4.378.1700  
Bangalore, India  
+91.80.6715.2001  
Istanbul, Turkey  
+90.216.250.7374  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)



Our powerful portfolio of brands:

**CADDY   ERICO   HOFFMAN   ILSCO   SCHROFF   TRACHTE**