

# 38 Offset Steel Eye Socket Rod Hanger



## CERTIFICATIONS



## FEATURES

Structural attachment used to join hanger rod to a structure

Provides full vertical rod adjustment

## SPECIFICATIONS

Table 1/2

| Catalog Number | Article Number | Material | Finish            | Rod Size (RS) | Hole Size 1 (HS1) | Hole Size 2 (HS2) |
|----------------|----------------|----------|-------------------|---------------|-------------------|-------------------|
| 038M0010EG     | 598290         | Steel    | Electrogalvanized | M10           | 13 mm             | 6.7 mm            |

Table 2/2


| Catalog Number | Article Number | Height (H) | Width (W) | C       | D     | Static Load |
|----------------|----------------|------------|-----------|---------|-------|-------------|
| 038M0010EG     | 598290         | 85 mm      | 29 mm     | 30.6 mm | 19 mm | 1112N       |

ADDITIONAL PRODUCT DETAILS

Load rating dependent on wood structure strength.

For 3/8" rod through 2" pipe, use two Model #43 Wood Drive Screws. For 3/8" rod through 4" pipe, use one Model #42 1/2" x 3" Lag Screw.

DIAGRAMS

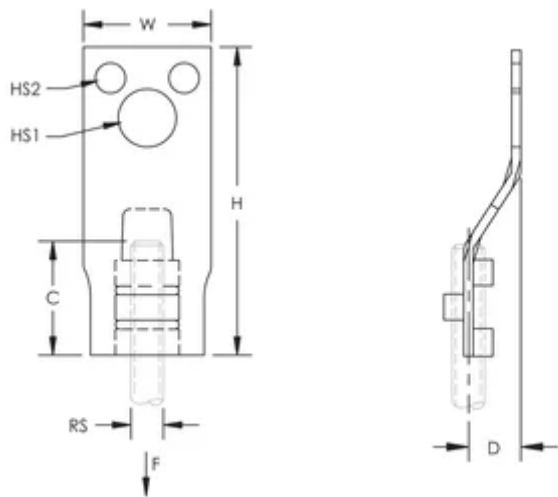

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221  
Option 1 – Customer Care  
Option 2 – Technical  
Support

Europe

Netherlands:  
+31 800-0200135  
France:  
+33 800 901 793

Europe

Germany:  
800 1890272  
Other Countries:  
+31 13 5835404

APAC

Shanghai:  
+ 86 21 2412 1618/19  
Sydney:  
+61 2 9751 8500



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE

