


# Mounting Profiles 19-Inch , CIP

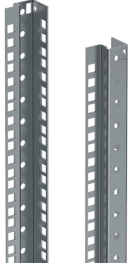

19" equipment can be easily fitted in floor standing enclosures, either in the factory or in the field, when these profiles are used.

## FEATURES

---

Description: Full height mounting profiles to achieve 482.6 mm (19") mounting requirements on all sides. Fully adjustable in depth.

Material: 2 mm zinc plated steel.

Pack quantity: 1 pair.

Mounting requirements: To be used in conjunction with CIB or CID profiles. For partial height mounting the CIWR is required.

## SPECIFICATIONS

---

**Thickness:** 2mm  
**Material:** Mild Steel  
**Finish:** Zinc Plated

Table 1/1

Catalog Number	Height	Width	Depth	Rack Units	Enclosure Material	Quick Ship
CIP20	1000mm	45mm	29mm	20U	Mild Steel	No
CIP22	1100mm	45mm	29mm	22U	Mild Steel	No
CIP24	1200mm	45mm	29mm	24U	Mild Steel	No
CIP29	1400mm	45mm	29mm	29U	Mild Steel	No
CIP33	1600mm	45mm	29mm	33U	Mild Steel	No
CIP38	1800mm	45mm	29mm	38U	Mild Steel	No
CIP42	2000mm	45mm	29mm	42U	Mild Steel	No
CIP47	2200mm	45mm	29mm	47U	Mild Steel	No

## WARNING

---

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.



Our powerful portfolio of brands:

**CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE**