


Eurorack Mobile Base/Plinth, 602x890

CATALOG NUMBER

23117-037

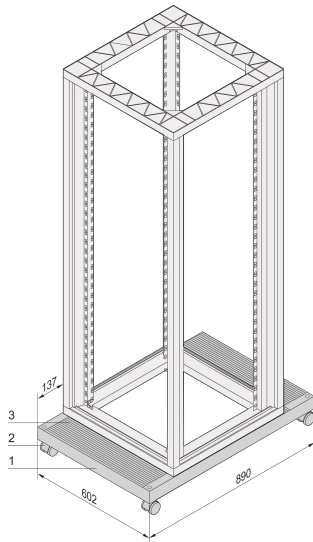

Aluminum mobile base plinth with load capacity of 300 kg, for aluminum cabinets with 600 mm breadth.

CERTIFICATIONS



FEATURES

For cabinets 600 mm wide, depth 600 or 800 mm

Static load-carrying capacity 300 kg

PRODUCT ATTRIBUTES

Color: Black Grey

Color Code: RAL 7021

Depth: 800mm

Finish: Powder Coated

Material: Steel

Package Quantity: 1

Product Family: Eurorack

Product Type: Cabinet/Rack Base

Type: Base Plinth

Width: 600mm

ADDITIONAL PRODUCT DETAILS

The jacking Feet for the mobile plinth are fitted from below.

They are adjusted with a screwdriver from above.

Tubber mat on request.

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab
Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Our powerful portfolio of brands:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE