


# EuropacPRO 19" Subrack Kit for Power Distribution Module, Unshielded, 3 U, 84 HP, 115 mm

## CATALOG NUMBER

**24563-100**

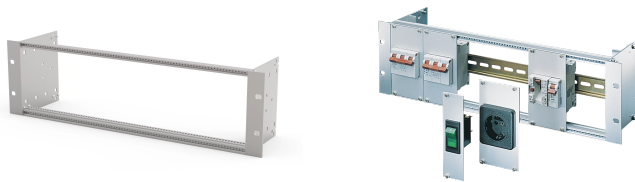

For mounting installation devices in accordance with DIN 43880 in sizes 1-3 with snap-in technology e.g. mounting sockets, circuit breakers or residual current circuit breaker. These can be fitted after the horizontal rail with lip DIN central rail (35/7.5) are fitted.

## CERTIFICATIONS



## FEATURES

For mounting installation devices in accordance with DIN 43880 in sizes 1-3 with snap-in technology e.g. mounting sockets, circuit breakers or residual current circuit breaker. These can be fitted after the horizontal rail with lip DIN central rail (35/7.5) are fitted

Modular frame to accept e.g. power distribution modules

Internal and external dimensions in accordance with the IEC 60297-3-101 and IEEE 1101.1 standards

Aluminium side panels

Horizontal rails type "light"

PRODUCT ATTRIBUTES

|                                         |
|-----------------------------------------|
| Product Type: Subrack/Chassis           |
| Rack Height: 3U                         |
| Rack Width: 84HP                        |
| Depth: 115mm                            |
| For Mounting: Power Distribution Module |
| EMC Shielding: No                       |
| Static Load: 2.5kg                      |
| Handle Included: No                     |
| Mounting: Rack                          |
| Complies With: IEC 60297-3-103          |
| Package Quantity: 1                     |
| Finish: Anodized; Passivated            |
| Height: 132.55mm                        |
| Material: Aluminum                      |
| Width: 482.6mm                          |

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

All locations  
+1.763.422.2661  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

Europe

Straubenhardt, Germany  
+49.7082.794.0  
Betschdorf, France  
+33.3.88.90.64.90  
Warsaw, Poland  
+48.22.209.98.35  
Assago, Italy  
+39.02.932.7141  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

Asia

Shanghai, China  
+86.21.2412.6943  
Qingdao, China  
+86.532.8771.6101  
Singapore  
+65.6768.5800  
Shin-Yokohama, Japan  
+81.45.476.0271  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

Middle East & India

Dubai, United Arab Emirates  
+971.4.378.1700  
Bangalore, India  
+91.80.6715.2001  
Istanbul, Turkey  
+90.216.250.7374  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)



Our powerful portfolio of brands:

CADDY   ERICO   HOFFMAN   ILSCO   SCHROFF   TRACHTE