


# Novastar Raised Top Cover

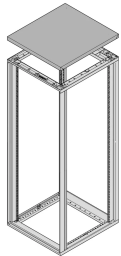

Raised top cover for better ventilation and heat escape. Novastar raised top cover is robust and not dismountable from the outside.

## CERTIFICATIONS



## FEATURES

Raised Top cover (31 mm) with all-round air gap of 10 mm

Top cover attached from the inside (no screws on the outside)

Suitable for placing heavy parts on the top cover

Incl. grounding

Robust version, load-carrying capacity 50 kg

## SPECIFICATIONS

- Width:** 553mm
- Product Type:** Cabinet/Rack Top Cover
- Material:** Steel

Table 1/2

Catalog Number	Depth	Package Quantity	Color	Color Code	Finish	Type
25230-037	800mm	1	Black Grey	RAL 7021	Powder Coated	Raised

CatalogNumber	Depth	Package Quantity	Color	Color Code	Finish	Type
25230-142	1000mm	1	Black Grey	RAL 7021	Powder Coated	Raised
25230-141	900mm	1	Black Grey	RAL 7021	Powder Coated	Raised
25230-039	500mm	1	Black Grey	RAL 7021	Powder Coated	Raised
25230-038	600mm	1	Black Grey	RAL 7021	Powder Coated	Raised

Table 2/2

Catalog Number	Quick Ship
25230-037	No
25230-142	No
25230-141	No
25230-039	No
25230-038	No

## ADDITIONAL PRODUCT DETAILS

---

Please order lifting eye separately if required.

## WARNING

---

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

### North America

All locations

+1.763.422.2661

Chat with us:

[nvent.com/schroff](https://nvent.com/schroff)

### Europe

Straubenhardt, Germany

+49.7082.794.0

Betschdorf, France

+33.3.88.90.64.90

Warsaw, Poland

+48.22.209.98.35

Assago, Italy

+39.02.932.7141

Chat with us:

[nvent.com/schroff](https://nvent.com/schroff)

### Asia

Shanghai, China

+86.21.2412.6943

Qingdao, China

+86.532.8771.6101

Singapore

+65.6768.5800

Shin-Yokohama, Japan

+81.45.476.0271

Chat with us:

[nvent.com/schroff](https://nvent.com/schroff)

### Middle East & India

Dubai, United Arab

Emirates

+971.4.378.1700

Bangalore, India

+91.80.6715.2001

Istanbul, Turkey

+90.216.250.7374

Chat with us:

[nvent.com/schroff](https://nvent.com/schroff)



Our powerful portfolio of brands:

**CADDY**

**ERICO**

**HOFFMAN**

**ILSCO**

**SCHROFF**

**TRACHTE**