


# Varistar CP Perforated, Seismic Base Plate, EMC, for Rear Cable Ducting

Varistar CP Base Plate for Rear Cable Ducting, plain for IP 55 or EMC applications.

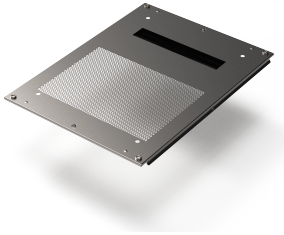

## FEATURES

Installation from outside

Cutout at rear

60 mm deep

Cable ducting with IP 55 / EMC gasket

## SPECIFICATIONS

**Product Type:** Cabinet/Rack Base

**Finish:** Hot-Dip Galvanized

**Material:** Steel

Table 1/2

Catalog Number	Width	Depth	Package Quantity	Complies With	Type	Works With
20630-327	600mm	1000mm	1	IEC 61587-1, IEC 61587-2, IEC 61587-3	Base Plate, Perforated	Varistar CP
20630-325	600mm	600mm	1	IEC 61587-1, IEC 61587-2, IEC 61587-3	Base Plate, Perforated	Varistar CP
20630-332	800mm	1200mm	1	IEC 61587-1, IEC 61587-2, IEC 61587-3	Base Plate, Perforated	Varistar CP

CatalogNumber	Width	Depth	Package Quantity	Complies With	Type	Works With
20630-331	800mm	1000mm	1	IEC 61587-1, IEC 61587-2, IEC 61587-3	Base Plate, Perforated	Varistar CP
20630-326	600mm	800mm	1	IEC 61587-1, IEC 61587-2, IEC 61587-3	Base Plate, Perforated	Varistar CP
20630-330	800mm	800mm	1	IEC 61587-1, IEC 61587-2, IEC 61587-3	Base Plate, Perforated	Varistar CP
20630-328	600mm	1200mm	1	IEC 61587-1, IEC 61587-2, IEC 61587-3	Base Plate, Perforated	Varistar CP
20630-329	800mm	600mm	1	IEC 61587-1, IEC 61587-2, IEC 61587-3	Base Plate, Perforated	Varistar CP

Table 2/2

Catalog Number	Quick Ship
20630-327	No
20630-325	No
20630-332	No
20630-331	No
20630-326	No
20630-330	No
20630-328	No
20630-329	No

## ADDITIONAL PRODUCT DETAILS

Varistar CP Base Plate for Rear Cable Ducting, plain for IP 55 or EMC applications.

Please purchase the grounding kit separately.

## WARNING

---

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

### North America

All locations  
+1.763.422.2661  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

### Europe

Straubenhardt, Germany  
+49.7082.794.0  
Betschdorf, France  
+33.3.88.90.64.90  
Warsaw, Poland  
+48.22.209.98.35  
Assago, Italy  
+39.02.932.7141  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

### Asia

Shanghai, China  
+86.21.2412.6943  
Qingdao, China  
+86.532.8771.6101  
Singapore  
+65.6768.5800  
Shin-Yokohama, Japan  
+81.45.476.0271  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

### Middle East & India

Dubai, United Arab Emirates  
+971.4.378.1700  
Bangalore, India  
+91.80.6715.2001  
Istanbul, Turkey  
+90.216.250.7374  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)



Our powerful portfolio of brands:

**CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE**